

## OS306-Series QUICK Start Guide

### Battery Installation



1. Locate the notches on the side of the unit's handle and pull the front of the handle forwards as shown above.



2. Attach a 9V battery (provided) to the black connector inside. The battery should snap into place. Swing the front of the handle back upwards to close the unit.

### How to turn on the unit

- Press the trigger of device to power on

### Quick Measurement

- Point thermometer at a target surface
- Pull and hold the trigger to begin scanning
- Release the trigger to stop scanning
- The data will be held for 30 seconds then the unit will power off

### Switch between Celsius and Fahrenheit


The default setting for the temperature unit is in Celsius. Please follow the below steps to change the temperature units to Fahrenheit.

- Press the "°C °F" Button
- You should now see the temperature displayed in °F (Fahrenheit)



### Field of View

- This unit has a distance ratio of 12:1
- When measuring a surface 300 mm away, a 25 mm area will be measured.

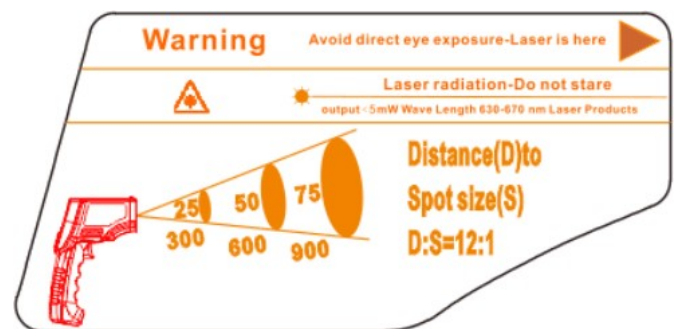

### Contact Information

If you need technical support, please call 1-888-826-6342.