


# Mica-Glass Insulated Ultra High Temperature Heater Hook-Up Wire



HTMG Series



- ✓ 450°C (842°F) Temperature Rating
- ✓ CSA Certified, NRTL and UL Listed
- ✓ Single Stranded 27% Nickel Coated Copper Conductor
- ✓ Mica Tape Insulation with Treated Glass Overbraid

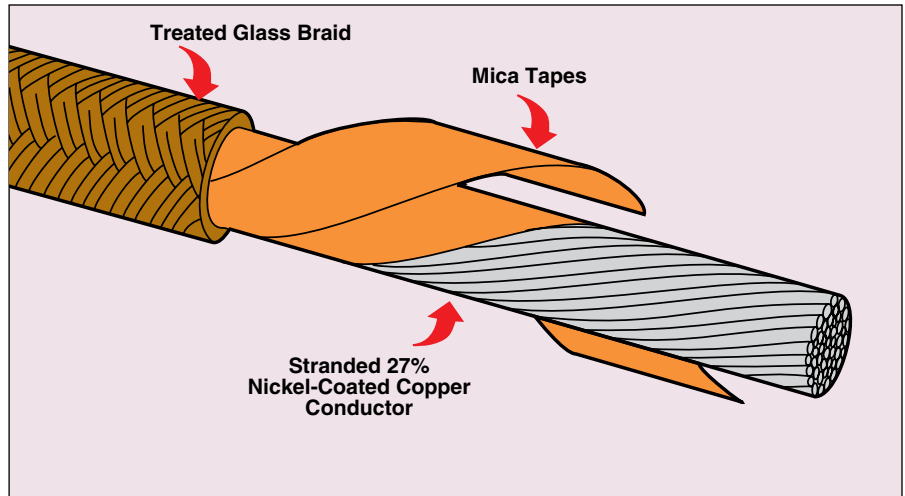

HTMG high-temperature lead wires are designed for appliances and industrial heating products—such as commercial food service equipment, heaters, heat treating furnaces, kilns, heater elements and other applications up to 450°C (842°F).

Discount Schedule	
50 to 99 ft.....	10%
100 to 199 ft.....	15%
200 to 499 ft.....	20%
499 ft. and up.....	25%

## To Order *Sold by the Foot*

Gage	Model No.	Stranded	Volts	Nominal OD mm (inch)	Approx Wt kg/300 m (lb/1000')
22	HTMG-1CU-322S/C	7 x 30	300	2.0 (0.08)	2.5 (5.5)
22	HTMG-1CU-622S/C		600	2.6 (0.10)	3.2 (7.0)
20	HTMG-1CU-320S/C	10 x 30	300	2.1 (0.08)	3.2 (7.0)
20	HTMG-1CU-620S/C		600	2.8 (0.11)	4.1 (9.0)
18	HTMG-1CU-318S/C	16 x 30	300	2.4 (0.10)	4.3 (9.5)
18	HTMG-1CU-618S/C		600	3.0 (0.12)	5.2 (11.5)
16	HTMG-1CU-316S/C	26 x 30	300	2.7 (0.11)	5.9 (13.0)
16	HTMG-1CU-616S/C		600	3.3 (0.13)	6.8 (15.0)
14	HTMG-1CU-314S/C	41 x 30	300	3.0 (0.12)	8.4 (18.5)
14	HTMG-1CU-614S/C		600	3.7 (0.14)	9.5 (21.0)
12	HTMG-1CU-312S/C	65 x 30	300	3.5 (0.14)	12.2 (27.0)
12	HTMG-1CU-612S/C		600	4.1 (0.16)	13.4 (29.5)
10	HTMG-1CU-310S/C	105 x 30	300	5.1 (0.20)	21.1 (46.5)
10	HTMG-1CU-610S/C		600	5.7 (0.22)	22.9 (50.5)
8	HTMG-1CU-308S/C	133 x 29	300	6.0 (0.23)	31.8 (70.0)
8	HTMG-1CU-608S/C		600	6.1 (0.26)	34.2 (75.5)

Standard Color: Natural (tan).

Ordering Example: (Qty = 100) HTMG-1CU-322S/C, a 100' spool of 22 gage stranded wire. See heater hook-up wire introduction for current carrying capacity and derating.