


# STANDARD DIMENSION ADAPTORS AND REDUCING BUSHINGS

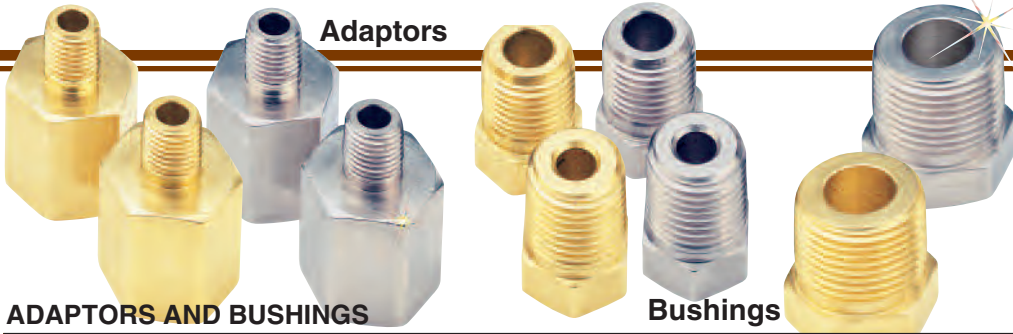

Adaptors

Bushings

- ✓ Rugged Design
- ✓ Available in Stainless Steel, Brass, or Carbon Steel
- ✓ Reduce Down to 1/8 NPT
- ✓ Adapt Up to 1 NPT


**MOST POPULAR  
MODELS HIGHLIGHTED!**

ADAPTORS AND BUSHINGS

## To Order (Specify Model Number)

NPT THREAD		ACROSS HEX FLATS INCHES	LENGTH INCHES	BRASS		STAINLESS STEEL	
MALE	FEMALE			MODEL NO.		MODEL NO.	
<b>REDUCING ADAPTORS</b>							
1/8	1/4	0.75	1.26	RA-18-14-BR		RA-18-14-SS	
1/8	1/2	1.06	1.58	RA-18-12-BR		RA-18-12-SS	
1/4	1/2	1.06	1.76	RA-14-12-BR		RA-14-12-SS	
1/2	3/4	1.31	2.02	RA-12-34-BR		RA-12-34-SS	
1/2	1	1 5/8	2.16	—		RA-12-1-SS	
7/16-20	1/4	9/16	1.25	—		RA-716-14M-SS	
7/16-20	1/4 female	3/4	1.31	—		RA-716-14F-SS	
<b>REDUCING BUSHINGS</b>							
1/4	1/8	0.56	1.06	RB-14-18-BR		RB-14-18-SS	
1/2	1/8	0.87	1.08	RB-12-18-BR		RB-12-18-SS	
1/2	1/4	0.87	1.08	RB-12-14-BR		RB-12-14-SS	
3/4	1/2	1.06	1.63	RB-34-12-BR		RB-34-12-SS	
1	1/2	1.37	1.37	RB-1-12-BR		RB-1-12-SS	
1	3/4	1.37	1.85	RB-1-34-BR		RB-1-34-SS	
1 1/4	3/4	1 3/4	1.47	—		RB-114-34-CS*	
1 1/4	1	1 3/4	1.47	—		RB-114-1-CS*	
1 1/2	1	2	1.58	—		RB-112-1-CS*	

## OMEGALOK® COMPRESSION FITTINGS

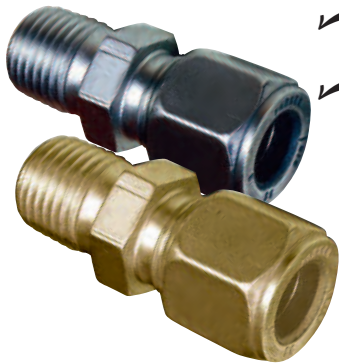

- ✓ Ferrule Design for Positive Pressure Seal
  - ✓ Heavy Duty Construction in Stainless Steel or Brass
  - ✓ For Protection Tube Diameters 1/16" up to 1/2"
- For metric compression fittings see page C-8.

\* Fittings are available only in carbon steel.  
Ordering Example: RB-12-14-SS, stainless steel  
1/2 male and 1/4 female reducing bushing.

**MOST POPULAR  
MODELS HIGHLIGHTED!**

## COMPRESSION FITTINGS

### To Order (Specify Model Number)

PROTECTION TUBE OD	MALE Th'd NPT	LENGTH mm (in)	BRASS MODEL NO.	316 SS MODEL NO.
1/16	1/16	24.6 (0.97)	N/A	SSLK-116-116
1/16	1/8	26.2 (1.03)	BRLK-116-18	SSLK-116-18
1/8	1/8	30.0 (1.18)	BRLK-18-18	SSLK-18-18
1/8	1/4	44.2 (1.74)	BRLK-18-14	SSLK-18-14
3/16	1/8	31.0 (1.22)	BRLK-316-18	SSLK-316-18
3/16	1/4	46.0 (1.81)	BRLK-316-14	SSLK-316-14
1/4	1/8	32.8 (1.29)	BRLK-14-18	SSLK-14-18
1/4	1/4	37.6 (1.48)	BRLK-14-14	SSLK-14-14
5/16	1/4	39.1 (1.54)	N/A	SSLK-516-14
3/8	1/4	40.4 (1.59)	BRLK-38-14	SSLK-38-14
3/8	3/8	40.4 (1.59)	BRLK-38-38	SSLK-38-38
3/8	1/2	46.0 (1.81)	BRLK-38-12	SSLK-38-12
1/2	1/2	49.3 (1.94)	BRLK-12-12	SSLK-12-12

Note: PTFE can only be used with stainless steel compression fittings.  
Ordering Example: BRLK-18-18, brass 1/8 NPT compression fitting for 1/8" OD protection tubes.

## Replacement Ferrules - (pkg of 10)

TUBE OD	BRASS	STAINLESS STEEL	PTFE
1/16	B-FER-1/16	SS-FER-1/16	T-FER-1/16
1/8	B-FER-1/8	SS-FER-1/8	T-FER-1/8
3/16	B-FER-3/16	SS-FER-3/16	T-FER-3/16
1/4	B-FER-1/4	SS-FER-1/4	T-FER-1/4
5/16	B-FER-5/16	SS-FER-5/16	T-FER-5/16
3/8	B-FER-3/8	SS-FER-3/8	T-FER-3/8
1/2	B-FER-1/2	SS-FER-1/2	T-FER-1/2

# METRIC THREAD ADAPTORS



Brass

Stainless Steel



CONVERT IMPERIAL AND METRIC THREADS

**MOST POPULAR MODELS HIGHLIGHTED!**

## To Order (Specify Model Number)

FEMALE NPT	MALE BSPT*	FLATS mm	LENGTH mm	BRASS		STAINLESS STEEL	
				MODEL NO.	MODEL NO.		
1/8	1/8-28	14	27.7	MTA1-1/8-1/8-BR	MTA1-1/8-1/8-SS		
1/4	1/4-19	19	36.1	MTA1-1/4-1/4-BR	MTA1-1/4-1/4-SS		
3/8	3/8-19	22	38.1	MTA1-3/8-3/8-BR	MTA1-3/8-3/8-SS		
1/2	1/2-14	27	49.3	MTA1-1/2-1/2-BR	MTA1-1/2-1/2-SS		
3/4	3/4-14	34	51.3	MTA1-3/4-3/4-BR	MTA1-3/4-3/4-SS		
1	1-11	41	58.4	MTA1-1-1-BR	MTA1-1-1-SS		
BSPT*	NPT						
1/4-19	1/4	19	36.3	MTA2-1/4-1/4-BR	MTA2-1/4-1/4-SS		
3/8-19	3/8	22	38.4	MTA2-3/8-3/8-BR	MTA2-3/8-3/8-SS		
1/2-14	1/2	27	49.8	MTA2-1/2-1/2-BR	MTA2-1/2-1/2-SS		
NPT	BSPP						
1/8	1/8-28	14	25.1	-	MTA3-1/8-1/8-SS		
1/4	1/4-19	19	33.5	MTA3-1/4-1/4-BR	MTA3-1/4-1/4-SS		
3/8	3/8-19	22	35.8	MTA3-3/8-3/8-BR	MTA3-3/8-3/8-SS		
1/2	1/2-14	27	44.2	MTA3-1/2-1/2-BR	MTA3-1/2-1/2-SS		
3/4	3/4-14	34	48.0	MTA3-3/4-3/4-BR	MTA3-3/4-3/4-SS		
1	1-11	41	53.3	MTA3-1-1-BR	MTA3-1-1-SS		
BSPP	NPT						
1/4-19	1/4	19	27.4	MTA4-1/4-1/4-BR	MTA4-1/4-1/4-SS		
3/8-19	3/8	22	32.3	MTA4-3/8-3/8-BR	MTA4-3/8-3/8-SS		
1/2-14	1/2	27	41.9	MTA4-1/2-1/2-BR	MTA4-1/2-1/2-SS		

\* ISO 228/1, BS 2779.

Ordering Examples: MTA1-1/8-1/8-BR, brass 1/8 NPT female to 1/8-28 BSPT male.  
MTA1-1/8-1/8-SS, stainless steel thread adaptor.

# METRIC OMEGALOK® COMPRESSION FITTINGS

FOR METRIC PROBES AND PROTECTION TUBES



## To Order Metric Compression Fittings (Specify Model Number)

Protection Tube OD	Male Th's	Th'd Type	Metric Protection Tube/NPT Thread		Metric Protection Tube/ BSP Taper Thread			Metric Protection Tube/ BSP Parallel Thread		
			Brass Model No.	316 Stainless Steel Model No.	Th'd Type	Brass Model No.	316 Stainless Steel Model No.	Th'd Type	Brass Model No.	316 Stainless Steel Model No.
1.5 mm	1/8	NPT	BRLK-M15-18	SSLK-M15-18	BSPT	BRLK-M15-18T	SSLK-M15-18T	BSPP	BRLK-M15-18P	SSLK-M15-18P
3.0 mm	1/8	NPT	BRLK-M30-18	SSLK-M30-18	BSPT	BRLK-M30-18T	SSLK-M30-18T	BSPP	BRLK-M30-18P	SSLK-M30-18P
4.5 mm	1/8	NPT	BRLK-M45-18	SSLK-M45-18	BSPT	BRLK-M45-18T	SSLK-M45-18T	-	N/A	N/A
6.0 mm	1/8	NPT	BRLK-M60-18	SSLK-M60-18	BSPT	BRLK-M60-18T	SSLK-M60-18T	-	N/A	N/A
3.0 mm	1/4	NPT	BRLK-M30-14	SSLK-M30-14	BSPT	BRLK-M30-14T	SSLK-M30-14T	BSPP	BRLK-M30-14P	SSLK-M30-14P
4.5 mm	1/4	NPT	BRLK-M45-14	SSLK-M45-14	BSPT	BRLK-M45-14T	SSLK-M45-14T	-	N/A	N/A
6.0 mm	1/4	NPT	BRLK-M60-14	SSLK-M60-14	BSPT	BRLK-M60-14T	SSLK-M60-14T	BSPP	BRLK-M60-14P	SSLK-M60-14P
8.0 mm	1/4	NPT	BRLK-M80-14	SSLK-M80-14	BSPT	BRLK-M80-14T	SSLK-M80-14T	-	N/A	N/A
3.0 mm	3/8	-	N/A	SSLK-M30-38	-	N/A	SSLK-M30-38T	-	N/A	SSLK-M30-38P
6.0 mm	3/8	NPT	BRLK-M60-38	SSLK-M60-38	BSPT	BRLK-M60-38T	SSLK-M60-38T	BSPP	BRLK-M60-38P	SSLK-M60-38P
3.0 mm	1/2	-	N/A	SSLK-M30-12	BSPT	BRLK-M30-12T	SSLK-M30-12T	BSPP	BRLK-M30-12P	SSLK-M30-12P
4.5 mm	1/2	-	N/A	SSLK-M45-12	BSPT	BRLK-M45-12T	SSLK-M45-12T	BSPP	BRLK-M45-12P	SSLK-M45-12P
6.0 mm	1/2	NPT	BRLK-M60-12	SSLK-M60-12	BSPT	BRLK-M60-12T	SSLK-M60-12T	BSPP	BRLK-M60-12P	SSLK-M60-12P
8.0 mm	1/2	NPT	BRLK-M80-12	SSLK-M80-12	BSPT	BRLK-M80-12T	SSLK-M80-12T	-	N/A	N/A

Note: PFA can only be used with stainless steel compression fittings.

Ordering Examples: BRLK-M30-18, brass 1/8 NPT thread compression fitting for 3.0 mm protection tube OD.  
BRLK-M60-18, compression fitting.

ACCESSORIES