


OMEGAFLEX® Chemical Tubing

PFA/FEP FORMULATION, METRIC DIAMETERS

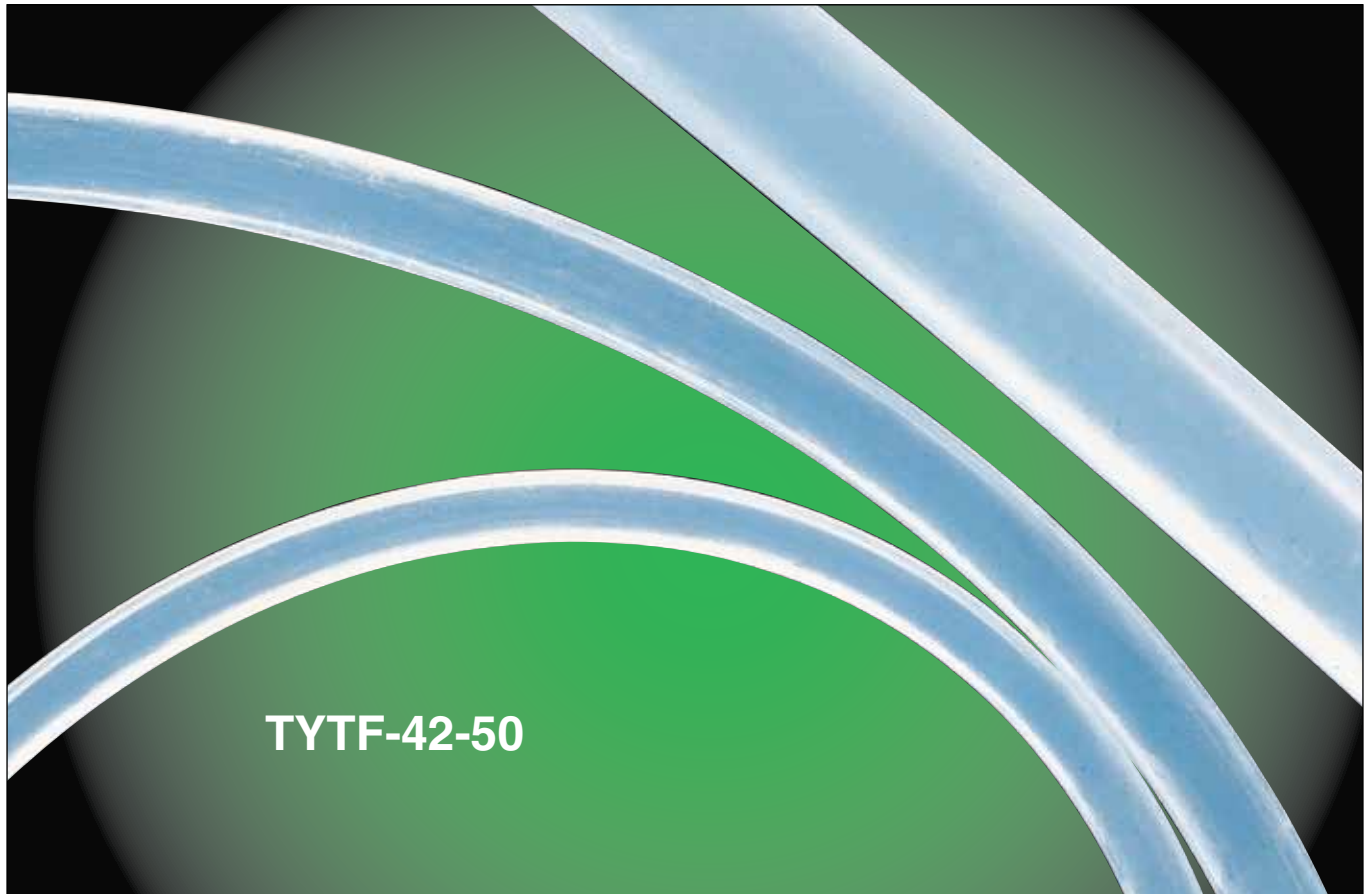

Specialty Tubing
Available!

To Order					
4 to 16 mm OD TUBING, Metric Diameters					
Model No.	Std Length (ft)	Wall (mm)	OD (mm)	ID (mm)	psi @73°F
TYTF-42-50	50	1	4	2	320
TYTF-42-100	100	1	4	2	320
TYTF-86-50	50	1	8	6	160
TYTF-86-100	100	1	8	6	160
TYTF-108-25	25	1	10	8	125
TYTF-108-50	50	1	10	8	125
TYTF-108-100	100	1	10	8	125
TYTF-1210-25	25	1	12	10	105
TYTF-1210-50	50	1	12	10	105
TYTF-1210-100	100	1	12	10	105
TYTF-1412-25	25	1	14	12	90
TYTF-1412-50	50	1	14	12	90
TYTF-1412-100	100	1	14	12	90

*Specifications shown are typical and are meant only as a guide. Field testing is recommended to find the actual values in the given application.

Notes: FEP is clear in color and can be heat sealed and heat bonded.

Sold in standard coil lengths of 5, 50, and 100'. FEP packages have no splices.

Consult Sales for available non-standard colors.

Ordering Example: TYTF-1210-100, 100 feet of tubing, 1 mm wall, 12 mm OD, 10 mm ID.

