


OMEGAFLEX® Chemical Tubing PTFE FORMULATION

TYTT-42-50

\$55

50' Spool

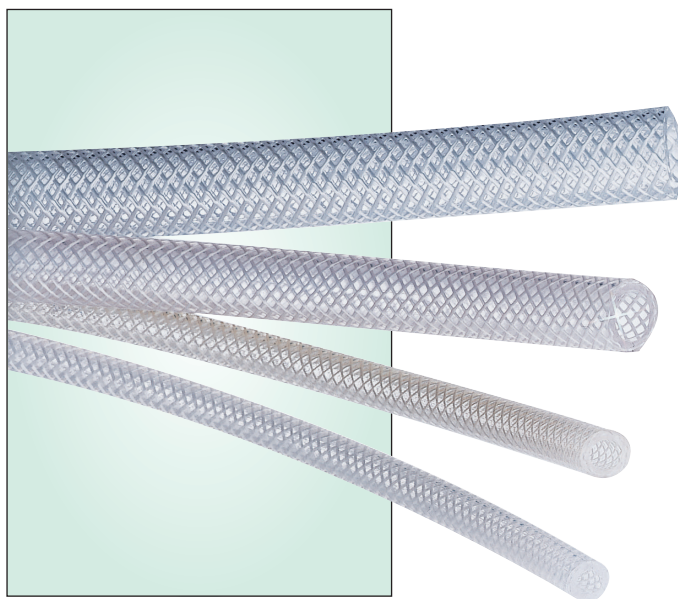

Think of OMEGA for Specialty Tubing!

- ✓ Coiled
- ✓ Kevlar® Wrapping
- ✓ Plastic and Metal Overbraiding
- ✓ Flexible Styles
- ✓ Custom Lengths



ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

4 to 16 mm OD TUBING, METRIC DIAMETERS

Model No.	Price	Std Length (ft)	Wall (mm)	OD (mm)	ID (mm)	psi @ 73°F
TYTT-42-50	\$55	50	1	4	2	320
TYTT-42-100	110	100	1	4	2	320
TYTT-64-50	85	50	1	6	4	210
TYTT-64-100	170	100	1	6	4	210
TYTT-86-50	144	50	1	8	6	160
TYTT-86-100	208	100	1	8	6	160
TYTT-108-25	100	25	1	10	8	125
TYTT-108-50	200	50	1	10	8	125
TYTT-108-100	400	100	1	10	8	125
TYTT-1210-25	110	25	1	12	10	105
TYTT-1210-50	220	50	1	12	10	105
TYTT-1210-100	440	100	1	12	10	105
TYTT-1412-25	130	25	1	14	12	90
TYTT-1412-50	260	50	1	14	12	90
TYTT-1412-100	520	100	1	14	12	90
TYTT-1614-25	160	25	1	16	14	80
TYTT-1614-50	320	50	1	16	14	80
TYTT-1614-100	640	100	1	16	14	80

Field testing is recommended to find the actual operating specifications in the given application.

Note: TFE is translucent white.

Sold in standard lengths of 25, 50, and 100'. TFE is coiled in 25' no-splice package, 50' maximum 2-splice package or 100' maximum 3-splice package.

Ordering Example: TYTT-1412-100, 100' of tubing, 1 mm wall, 14 mm OD, 12 mm ID, \$520.



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488

FRANCE

www.omega.fr

Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl

Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters