



STEAM, AIR AND GAS APPLICATIONS TO 398°C (750°F) GCHI/GCHIB Series


Dimensions: cm (in)
GCHI-06

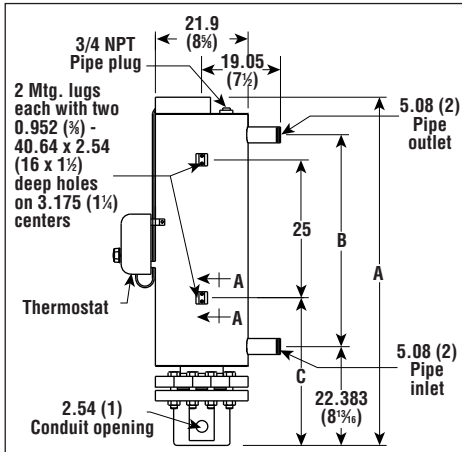

GCHIB-18

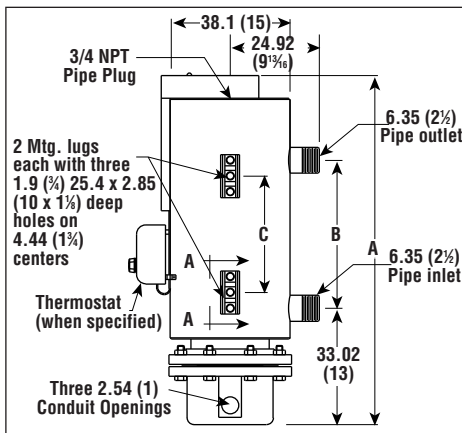

GCHI-27

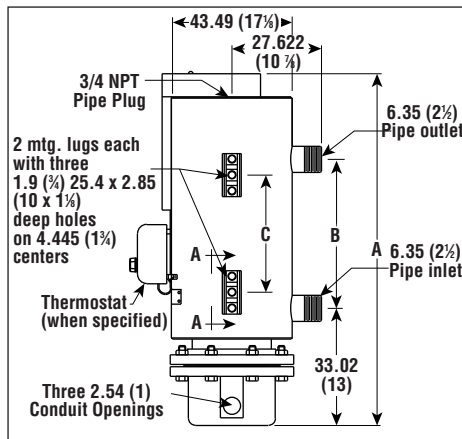

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

kW	Volts	Ckt & Phase	Dimensions: in			Model No.	Price	Wt. (lb)
			A	B	C			
Series 06—5", 150 lb Carbon Steel Vessel—6 INCOLOY Elements¹ (23 W/in²) with Thermostat								
9	480	1-1	41%	30	11%	GCHI-06-009P-E1/480	\$5450	135
9	480	1-3	41%	30	11%	GCHI-06-009P-E1/480/3P	5450	135
12	240	1-1	48%	37	14%	GCHI-06-012P-E1/240	6000	164
12	240	1-3	48%	37	14%	GCHI-06-012P-E1/240/3P	6000	164
12	480	1-1	48%	37	14%	GCHI-06-012P-E1/480	6000	164
12	480	1-3	48%	37	14%	GCHI-06-012P-E1/480/3P	6000	164
20	240	1-1	60%	48 1/2	20%	GCHI-06-020P-E1/240	7100	195
20	240	1-3	60%	48 1/2	20%	GCHI-06-020P-E1/240/3P	7100	195
20	480	1-1	60%	48 1/2	20%	GCHI-06-020P-E1/480	7100	195
20	480	1-3	60%	48 1/2	20%	GCHI-06-020P-E1/480/3P	7100	195
25	240	1-1	73%	61%	27%	GCHI-06-025P-E1/240	8150	212
25	480	1-3	73%	61%	27%	GCHI-06-025P-E1/480/3P	8150	212
25	240	1-1	73%	61%	27%	GCHI-06-025P-E1/240	8150	212
25	480	1-3	73%	61%	27%	GCHI-06-025P-E1/480/3P	8150	212
30	240	1-3	86%	74%	33%	GCHI-06-030P-E1/240/3P	9200	240
30	480	1-3	86%	74%	33%	GCHI-06-030P-E1/480/3P	9200	240
Series 18—8", 150 lb Carbon Steel Vessel—18 Baffled INCOLOY Elements¹ (20 W/in²)								
30	240	3-3	54%	32 1/16	29%	GCHIB-18-030P-E1/240	\$12,300	350
30	480	3-3	54%	32 1/16	29%	GCHIB-18-030P-E1/480	12,300	350
40	240	3-3	61%	39 1/16	36%	GCHIB-18-040P-E1/240	13,700	420
40	480	3-3	61%	39 1/16	36%	GCHIB-18-040P-E1/480	13,700	420
50	240	3-3	68%	47%	43%	GCHIB-18-050P-E1/240	15,200	480
50	480	3-3	68%	47%	43%	GCHIB-18-050P-E1/480	15,200	480
Series 27—10", 150 lb Carbon Steel Vessel—27 INCOLOY® Elements¹ (15 W/in²)								
50	240	3-3	68%	43	39 1/2	GCHI-27-050P-E1/240	\$18,850	400
50	480	3-3	68%	43	39 1/2	GCHI-27-050P-E1/480	18,850	400
60	240	3-3	75%	50	46 1/2	GCHI-27-060P-E1/240	20,850	440
60	480	3-3	75%	50	46 1/2	GCHI-27-060P-E1/480	20,850	440
70	240	3-3	81%	56	52 1/2	GCHI-27-070P-E1/240	22,550	480
70	480	3-3	81%	56	52 1/2	GCHI-27-070P-E1/480	22,550	480
80	240	3-3	91%	66	62 1/2	GCHI-27-080P-E1/240	25,400	520
80	480	3-3	91%	66	62 1/2	GCHI-27-080P-E1/480	25,400	520
90	240	3-3	100%	75	71 1/2	GCHI-27-090P-E1/240	27,950	560
90	480	3-3	100%	75	71 1/2	GCHI-27-090P-E1/480	27,950	560

¹ Outlet gas temperature must be kept below both maximum sheath and vessel temperature or element and heater damage may occur.

Note: Refer to the Controls section for side mounted controls or control panels.

Ordering Examples: GCHIB-18-030P-E1/480, 30 kW, 3-phase, 480V heater, \$12,300.

GCHI-06-025P-E1/240, 25 kW, 1-phase, 240V heater, \$8150.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters