

IMMERSION HEATER WITH STAINLESS STEEL WETTED CONSTRUCTION, 1 NPT

ARTMS Series Starts at

\$500



NRTL/C

- ✓ Passivated Stainless Steel Sheath for Weak Corrosive Solutions
- ✓ 0.75 to 3 kW

- ✓ 120, and 240 Vac, 1 phase
- ✓ Integral Thermostat

The OMEGALUX® ARTMS Series Immersion Heaters feature all passivated stainless steel wetted construction, ideal for process solutions with a 5 to 9 pH range.


Note: This integral thermostat functions as a temperature control only. This is not a fail safe device. An approved pressure and/or temperature control should be used with

SPECIFICATIONS


Wattage: 0.75 to 3 kW
 Power: 120, 240 Vac, 1 phase
 Sheath: 0.315" diameter passivated stainless steel
 Screw Plug: 1 NPT stainless steel
 Thermostat: Bulb and capillary tube
 Enclosure: E1 general purpose, NEMA-1 rated, or E2 moisture resistant/explosion resistant enclosure²

CAUTION AND WARNING!



See ARTM-3 for warnings.

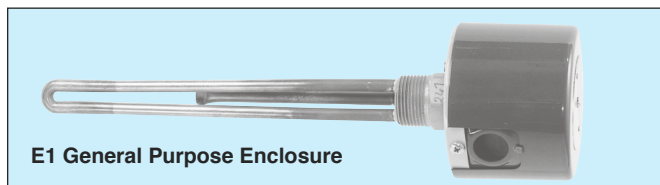

E1 General Purpose Enclosure

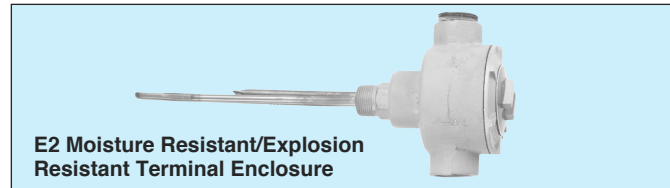

E2 Moisture Resistant/Explosion Resistant Terminal Enclosure

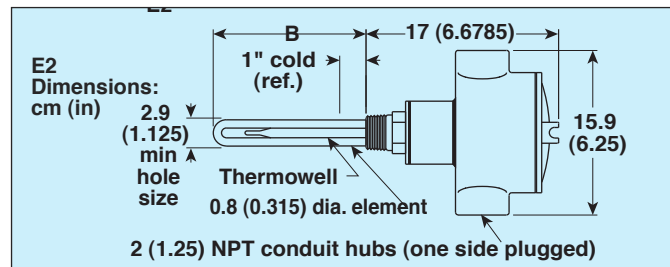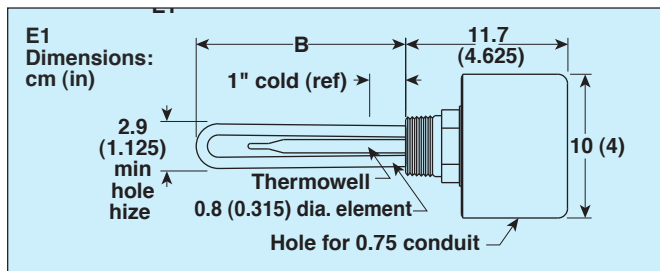

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

kW	W/in ²	No. Htg. Elem.	Dim. B in (cm)	Temp Range (60 to 187°F)		Temp Range (60 to 240°F)		Temp Range (0 to 127°F)		Wt. lb (kg)
				Model No.	Price	Model No.	Price	Model No.	Price	
ARTMS Series with E1 General Purpose Enclosure¹										
0.75	64	1	6 ⁵ / ₁₆ (16)	ARTMS-750/*	\$500	ARTMS-750TH/*	\$500	ARTMS-750TL/*	\$500	2 (1)
1.0	85	1	6 ⁵ / ₁₆ (16)	ARTMS-1000/*	525	ARTMS-1000TH/*	525	ARTMS-1000TL/*	525	2 (1)
1.25	83	1	8 ¹ / ₁₆ (20)	ARTMS-1250/*	525	ARTMS-1250TH/*	525	ARTMS-1250TL/*	525	3 (1)
1.5	86	1	9 ¹ / ₄ (23)	ARTMS-1500/*	525	ARTMS-1500TH/*	525	ARTMS-1500TL/*	525	3 (1)
2.0	83	1	12 ¹ / ₄ (31)	ARTMS-2000/*	550	ARTMS-2000TH/*	550	ARTMS-2000TL/*	550	3 (1)
2.5	79	1	16 ¹ / ₄ (41)	ARTMS-2500/*	575	ARTMS-2500TH/*	575	ARTMS-2500TL/*	575	3 (1)
3.0	78	1	19 ⁷ / ₁₆ (50)	ARTMS-3000/240V	600	ARTMS-3000TH/240V	600	ARTMS-3000TL/240V	600	3 (1)
ARTMS Series with E2 Moisture Resistant/Explosion Resistant Enclosure²										
0.75	64	1	6 ⁵ / ₁₆ (16)	ARTMS-750E2/*	\$725	ARTMS-750E2TH/*	\$725	ARTMS-750E2TL/*	\$725	5 (2)
1.0	85	1	6 ⁵ / ₁₆ (16)	ARTMS-1000E2/*	750	ARTMS-1000E2TH/*	750	ARTMS-1000E2TL/*	750	5 (2)
1.25	83	1	8 ¹ / ₁₆ (20)	ARTMS-1250E2/*	750	ARTMS-1250E2TH/*	750	ARTMS-1250E2TL/*	750	5 (2)
1.5	86	1	9 ¹ / ₄ (23)	ARTMS-1500E2/*	750	ARTMS-1500E2TH/*	750	ARTMS-1500E2TL/*	750	6 (3)
2.0	83	1	12 ¹ / ₄ (31)	ARTMS-2000E2/*	775	ARTMS-2000E2TH/*	775	ARTMS-2000E2TL/*	775	6 (3)
2.5	79	1	16 ¹ / ₄ (41)	ARTMS-2500E2/*	800	ARTMS-2500E2TH/*	800	ARTMS-2500E2TL/*	800	6 (3)
3.0	78	1	19 ⁷ / ₁₆ (50)	ARTMS-3000E2/240V	825	ARTMS-3000E2TH/240V	825	ARTMS-3000E2TL/240V	825	6 (3)

¹ Heaters with general purpose enclosures are UL Listed and CSA certified.

² Heaters with moisture resistant/explosion resistant enclosures are CSA NRTL/C certified.

* Designate voltage, "120" for 120 Vac or "240" for 240 Vac. Those numbers already containing "240" are available only in that voltage.

Ordering Example: ARTMS-750/120, 750 W heater, 60 to 187°F thermostat range, 120 Vac, \$500.

F



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters