



FLUOROPOLYMER COVERED IMMERSION HEATERS


GTF and GTFL Series

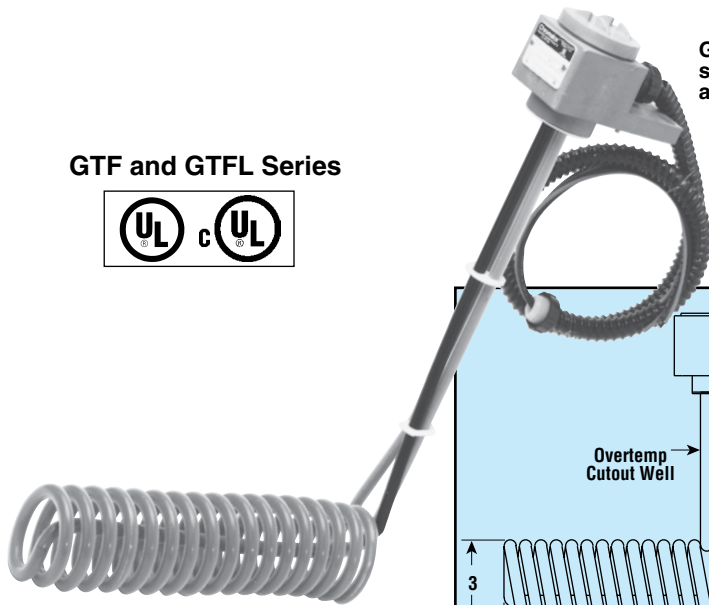

GTFL-11 shown smaller than actual size.

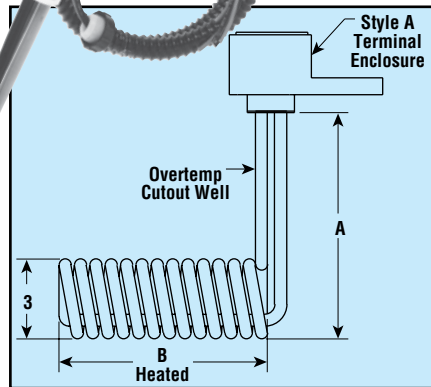

GTFL-11 shown smaller than actual size.

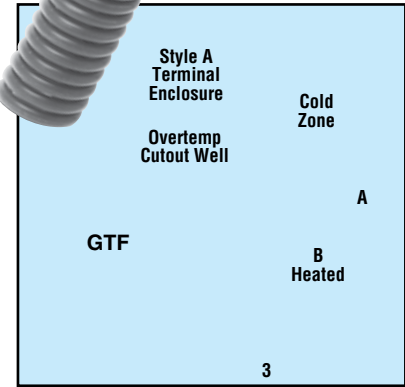

- ✓ GTF—Side Mount
- ✓ GTFL—L-Shaped
- ✓ Fluoropolymer Covered Stainless Steel Elements
- ✓ 10 W/in²
- ✓ 1 to 6 kW
- ✓ 120, 240 and 480V, 1 Phase
- ✓ Moisture Resistant Terminal Enclosure

FEATURES

- ✓ Moisture Resistant Terminal Enclosure
- ✓ Side Mounted Vertical Construction with Mounting Bracket (GTF Only)
- ✓ Side Mounted Horizontal Heater L-Shaped (GTFL Only)
- ✓ Overtemperature Protection One Time Use Thermal Fuse (260°F), Field Replaceable
- ✓ Polypropylene Guard, Order Separately
- ✓ Optional Riser Heights Available (GTFL Only)

To Order

kW	Volts	W/in ²	Phase	DIM (in)		Fluoropolymer Model No.	(lb)	Guard* Model No.
				A	B			
GTF — Side Mount								
1	120	10	1	11	6	GTF-11	7	GTF-1G
1	240	10	1	11	6	GTF-12	7	
2	240	10	1	17	10	GTF-22	8	GTF-2G
2	480	10	1	17	10	GTF-24	8	
3	240	10	1	23	14	GTF-32	13	GTF-3G
3	480	10	1	23	14	GTF-34	13	
4	240	10	1	29	18	GTF-42	15	GTF-4G
4	480	10	1	29	18	GTF-44	15	
5	240	10	1	35	23	GTF-52	18	GTF-5G
5	480	10	1	35	23	GTF-54	18	
6	240	10	1	40	27	GTF-62	21	GTF-6G
6	480	10	1	40	27	GTF-64	21	
GTFL — L-Shaped								
1	120	10	1	12	9	GTFL-11	8	GTFL-1G
1	240	10	1	12	9	GTFL-12	8	
2	240	10	1	18	13	GTFL-22	9	GTFL-2G
2	480	10	1	18	13	GTFL-24	9	
3	240	10	1	18	17	GTFL-32	13	GTFL-3G
3	480	10	1	18	17	GTFL-34	13	
4	240	10	1	18	21	GTFL-42	16	GTFL-4G
4	480	10	1	18	21	GTFL-44	16	
5	240	10	1	18	25	GTFL-52	18	GTFL-5G
5	480	10	1	18	25	GTFL-54	18	
6	240	10	1	18	29	GTFL-62	21	GTFL-6G
6	480	10	1	18	29	GTFL-64	21	

* Guard (not shown). Order separately by guard model number. Guard adds approximately 1/2" to overall heater dimensions.

Ordering Examples: GTF-62, 240V, 6 kW, side mount immersion heater, and GTF-6G, heater guard, GTFL-11, 120V, 1 kW, L-shaped immersion heater, and GTFL-1G, heater guard.