


SEAMLESS STRIP HEATERS WITHOUT MOUNTING TABS

SSE, SSEM & SSNHM Series

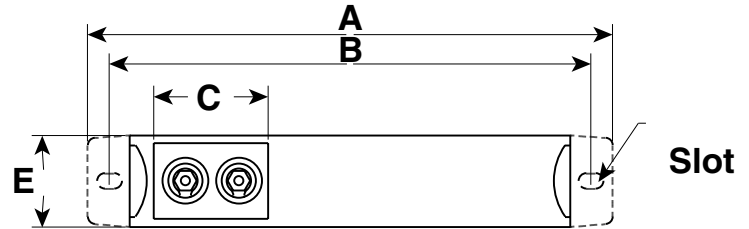

- ✓ 4 cm (1¹¹/₁₆") or 2.9 cm (1¹/₈") Wide
- ✓ Rugged, Reliable, Premium Quality
- ✓ 200 to 2550 Watts
- ✓ 2 Terminals One End
- ✓ Seamless Construction
- ✓ Select Rust Resisting Iron or Monel Sheath

Seamless strip elements are supplied without mounting tabs as standard. Overall length (dimension A) is with mounting tab; dimension D is length without mounting tabs.


SPECIFICATIONS

Sheath Material: Iron or Monel (SSNHM available only with Monel sheath)

Maximum Sheath Temperature: Iron, 750°F; Monel, 950°F

Power: 120 or 240 Vac

- C (Terminal Base)**
 1 ⁷/₈ for SSE and SSEM
 1 ⁵/₈ for SSNHM
- E (Width)**
 1 ¹¹/₁₆ for SSE and SSEM
 1 ¹/₈ or SSNHM

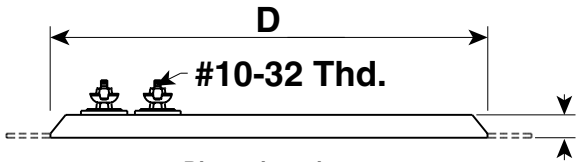

Dimensions: in

| To Order | | | | | | |
|-------------------------------------|-------------------------------------|-------------------------------------|-------|---------------------|------------------------|----------------|
| Dimensions: in (cm) | | | Watts | W/in ² † | Monel Sheath Model No. | Weight lb.(kg) |
| A | B | D | | | | |
| 8 ¹ / ₈ (21) | 7 ⁷ / ₈ (19) | 6 ⁵ / ₈ (17) | 200 | 19 | SSNHM-08/120 | 0.36(0.16) |
| 9 ¹ / ₈ (24) | 8 ¹ / ₈ (23) | 8 ¹ / ₈ (21) | 275 | 19 | SSNHM-09/120 | 0.38(0.17) |
| 11 ¹ / ₈ (28) | 10 ³ / ₈ (26) | 9 ¹ / ₈ (24) | 300 | 16 | SSNHM-11/120 | 0.50(0.22) |
| 12 ¹ / ₈ (31) | 11 ¹ / ₈ (29) | 10 ³ / ₈ (27) | 320 | 16 | SSNHM-12/* | 0.63(0.29) |
| 14 ¹ / ₈ (36) | 13 ³ / ₈ (34) | 12 ³ / ₈ (32) | 375 | 14 | SSNHM-14/* | 0.70(0.32) |
| 15 ¹ / ₈ (40) | 14 ³ / ₈ (37) | 13 ³ / ₈ (35) | 415 | 14 | SSNHM-15/* | 0.75(0.34) |
| 18 (46) | 17 ¹ / ₄ (44) | 16 ¹ / ₂ (42) | 495 | 13 | SSNHM-18/* | 1.40(0.64) |
| 19 ¹ / ₈ (50) | 18 ³ / ₈ (48) | 18 ¹ / ₈ (46) | 550 | 13 | SSNHM-19/* | 1.40(0.64) |
| 21 ¹ / ₈ (54) | 20 ³ / ₈ (52) | 19 ³ / ₈ (50) | 600 | 13 | SSNHM-21/* | 1.63(0.74) |
| 22 ¹ / ₈ (57) | 21 ³ / ₈ (56) | 22 ¹ / ₈ (56) | 625 | 13 | SSNHM-22/* | 1.79(0.81) |
| 23 ¹ / ₈ (61) | 23 ³ / ₈ (59) | 22 ³ / ₈ (57) | 675 | 13 | SSNHM-24/* | 1.81(0.82) |
| 25 ¹ / ₈ (65) | 24 ³ / ₈ (63) | 24 ¹ / ₈ (62) | 725 | 13 | SSNHM-25/* | 2.06(0.93) |
| 27 ¹ / ₈ (70) | 26 ³ / ₈ (68) | 26 ¹ / ₈ (66) | 800 | 13 | SSNHM-27/* | 2.25(0.10) |

* Designate voltage, i.e.; insert 120 for 120 Vac or 240 for 240 Vac. Model numbers containing /120 or /240 are only available in that voltage. For mounting tab specify "-with mounting tabs" as suffix for an additional cost.

Ordering Example: SSNHM-14/120, seamless strip heater without mounting tabs, 120 Vac, Monel sheath.

| To Order | | | | | | | |
|--------------------------------------|--------------------------------------|--------------------------------------|-------|---------------------|--------------------------------------|------------------------|-------------|
| Dimensions: in (cm) | | | Watts | W/in ² † | Rust-Resisting Iron Sheath Model No. | Monel Sheath Model No. | Wt. lb (kg) |
| A | B | D | | | | | |
| 8 ¹ / ₈ (21) | 7 ⁷ / ₈ (19) | 6 ⁵ / ₈ (17) | 200 | 13 | SSE-820/120 | SSEM-820/120 | 0.65 (0.29) |
| 10 ¹ / ₈ (27) | 9 ¹ / ₈ (25) | 9 ¹ / ₈ (23) | 275 | 11 | SSE-1027/* | SSEM-1027/* | 0.76 (0.34) |
| 12 ¹ / ₈ (31) | 11 ¹ / ₈ (29) | 10 ³ / ₈ (27) | 320 | 11 | SSE-1232/* | SSEM-1232/* | 0.88 (0.40) |
| 14 ¹ / ₈ (36) | 13 ³ / ₈ (34) | 12 ³ / ₈ (32) | 375 | 10 | SSE-1437/* | SSEM-1437/* | 1.0 (0.45) |
| 15 ¹ / ₈ (39) | 14 ³ / ₈ (37) | 13 ³ / ₈ (35) | 415 | 10 | SSE-1541/* | SSEM-1541/* | 1.14 (0.51) |
| 18 (46) | 17 ¹ / ₄ (44) | 16 ¹ / ₂ (42) | 500 | 10 | SSE-1849/* | SSEM-1849/* | 1.40 (0.64) |
| 19 ¹ / ₈ (50) | 18 ³ / ₈ (48) | 18 ¹ / ₈ (46) | 550 | 10 | SSE-1955/* | SSEM-1955/* | 1.50 (0.68) |
| 21 ¹ / ₈ (54) | 20 ³ / ₈ (52) | 19 ³ / ₈ (50) | 625 | 10 | SSE-2060/* | SSEM-2060/* | 1.63 (0.74) |
| 23 ¹ / ₈ (61) | 23 ³ / ₈ (59) | 22 ³ / ₈ (57) | 750 | 10 | SSE-2467/* | SSEM-2467/* | 1.81 (0.82) |
| 25 ¹ / ₈ (65) | 24 ³ / ₈ (63) | 24 ¹ / ₈ (61) | 800 | 10 | SSE-2572/* | SSEM-2572/* | 2.06 (0.93) |
| 30 ¹ / ₈ (78) | 29 ³ / ₈ (45) | 28 ³ / ₈ (71) | 1000 | 10 | SSE-3085/* | SSEM-3085/* | 2.38 (0.11) |
| 33 ¹ / ₈ (85) | 32 ³ / ₈ (82) | 31 ³ / ₈ (79) | 1250 | 12 | SSE-3392/* | SSEM-3392/* | 2.69 (0.12) |
| 36 (86) | 34 ³ / ₈ (89) | 33 ³ / ₈ (85) | 1500 | 13 | SSE-3611/* | SSEM-3611/* | 2.90 (0.13) |
| 38 ¹ / ₈ (98) | 37 ³ / ₈ (95) | 36 ³ / ₈ (93) | 1500 | 12 | SSE-3817/* | SSEM-3817/* | 3.20 (0.15) |
| 42 ¹ / ₈ (108) | 41 ³ / ₈ (105) | 40 ³ / ₈ (102) | 1500 | 11 | SSE-4315/* | SSEM-4315/* | 3.40 (0.15) |
| 48 (122) | 46 ³ / ₈ (119) | 45 ³ / ₈ (116) | 1650 | 10 | SSE-4816/* | SSEM-4816/* | 3.80 (0.17) |
| 54 (137) | 52 ³ / ₈ (133) | 51 ³ / ₈ (131) | 1875 | 10 | SSE-5418/* | SSEM-5418/* | 4.20 (0.19) |
| 64 (163) | 62 ³ / ₈ (160) | 61 ³ / ₈ (156) | 2250 | 10 | SSE-6422/240 | SSEM-6422/240 | 5.12 (0.23) |
| 72 (183) | 70 ³ / ₈ (180) | 69 ³ / ₈ (177) | 2550 | 10 | SSE-7225/240 | SSEM-7225/240 | 5.75 (0.26) |

/* Designate voltage, i.e.; insert 120 for 120 Vac or 240 for 240 Vac. Model numbers containing /120 or /240 are only available in that voltage.
 † To determine maximum allowable watt density, visit us online. For mounting tab specify "-with mounting tabs" as suffix for an additional cost.
Ordering Example: SSEM-3392/120, seamless strip heater without mounting tabs, 120 Vac, Monel sheath.