

DC POWER SUPPLIES

PSU-93



SPECIFICATIONS

Input Voltage: 120V \pm 10%, 60 Hz

Output Voltage: 16 to 23 Vdc
(see table)

Output Voltage Connection:

Screw terminals, up to 16 AWG,
#6 to 32 screws

Ambient Operating Temperature:

0 to 50°C (32 to 122°F)

Dimensions: 55.9 W x 49.3 H x 48.3 mm D
(2.20 x 1.94 x 1.90")

Weight: 198 g (7 oz)

PSU-93 plug-in power supply provides an unregulated 16 to 23V supply for electronic equipment.



PSU-93 shown smaller than actual size.



Input	105 Vac	120 Vac	130 Vac
Output (mA)	Output Vdc	Output Vdc	Output Vdc
No Load	0	20.0	23.0
	50	17.8	20.5
	100	16.5	19.5
	200	15.0	17.5
Full Load	300	13.5	16.0

FPW-15



FPW-15 shown smaller than actual size.

The FPW-15 is a regulated 15 Vdc supply for electronic equipment.

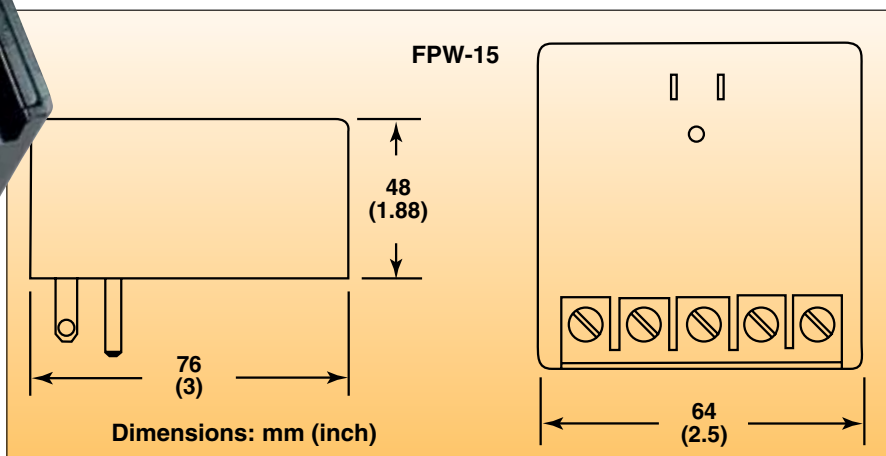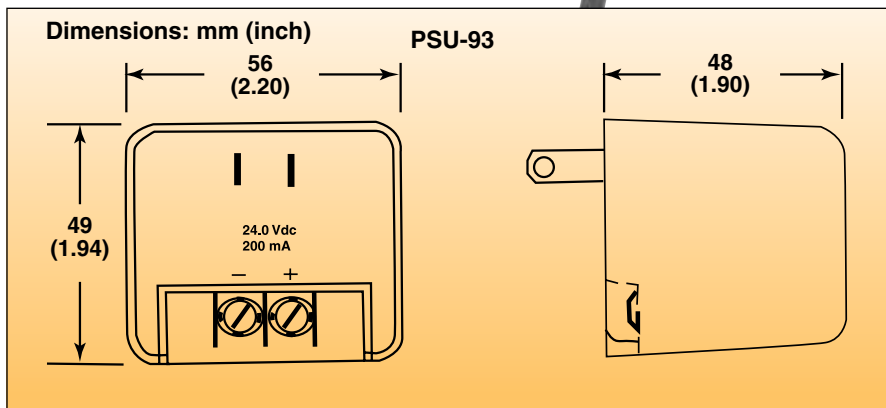

SPECIFICATIONS

Input Voltage: 120 V \pm 10%, 60 Hz

Output Voltage: 15 Vdc at 400 mA

Output Voltage Connection: Screw terminals, #6, up to 16 AWG

Ambient Operating Temperature:

0 to 50°C (32 to 122°F)

Dimensions: 63.5 W x 76.2 H x 47.6 mm D
(2.5 x 3 x 1.9")

To Order

Model No.	Description
PSU-93	24 Vdc, 200 mA
FPW-15	15 Vdc, 400 mA

Ordering Examples: PSU-93, 24 Vdc power supply.

FPW-15, 15 Vdc power supply.