


## PFA Safety Coated Liquid-In-Glass Thermometers

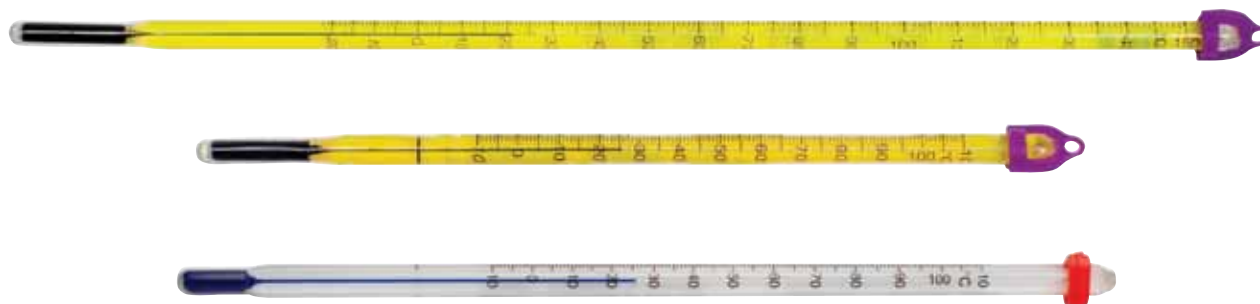

Safety coated thermometers.

These thermometers have added safety and protection from breakage! In the event of breakage, the PFA fluoropolymer safety coating keeps the liquid and glass encapsulated. Ideal for use in chemical laboratories, universities, scientific institutions, food and beverage processing, petrochemical laboratories, pharmaceutical industry, medical industry, manufacturers, dairies, breweries and distilleries.

These thermometers feature a multi-language (English, French, German, Italian, Portuguese and Spanish) Statement of Accuracy indicating accuracy traceable to

NIST and DAkkS. Each item is tested and calibrated in our exclusive triple accredited/registered ISO/IEC 17025:2005, A2LA accredited laboratory against equipment whose calibration is traceable to NIST and DAkkS. They feature a Statement of Accuracy indicating accuracy traceable to NIST. Each item is tested and calibrated in our exclusive triple accredited/registered ISO/IEC 17025:2005, A2LA accredited laboratory against equipment whose calibration is traceable to NIST.

| To Order                              |             |           |           |               |            |                                   |                    |
|---------------------------------------|-------------|-----------|-----------|---------------|------------|-----------------------------------|--------------------|
| Model No.                             | Type        | Range     | Divisions | Length        | Immersion  | Accuracy (Scale Divisions)        | Traceable to DAkkS |
| <b>Partial Immersion Thermometers</b> |             |           |           |               |            |                                   |                    |
| GT-30591T                             | Yellow Back | -10/110°C | 1         | 200 mm (7.9") | 50 mm (2") | 1                                 | Yes                |
| GT-30593T                             | Yellow Back | -10/150°C | 1         | 200 mm (7.9") | 50 mm (2") | 1, 1.5 above 110°C                | Yes                |
| GT-30597T                             | Yellow Back | 20/230°F  | 2         | 200 mm (7.9") | 50 mm (2") | 1                                 | Yes                |
| GT-30599T                             | Yellow Back | 20/300°F  | 2         | 200 mm (7.9") | 50 mm (2") | 1, 1.5 above 230°F                | Yes                |
| GT-30507T                             | Yellow Back | -10/70°C  | 0.5       | 300 mm (12")  | 76 mm (3") | 1                                 | Yes                |
| GT-30505T                             | Yellow Back | -20/110°C | 1         | 300 mm (12")  | 76 mm (3") | 1                                 | Yes                |
| GT-30515T                             | Yellow Back | -20/150°C | 1         | 300 mm (12")  | 76 mm (3") | 1, 1.5 above 110°C                | Yes                |
| GT-30535T                             | Yellow Back | 0/230°F   | 2         | 300 mm (12")  | 76 mm (3") | 1                                 | Yes                |
| GT-30545T                             | Yellow Back | 0/300°F   | 2         | 300 mm (12")  | 76 mm (3") | 1.5, 2 above 230°F                | Yes                |
| GT-30525T                             | Yellow Back | -10/260°C | 1         | 350 mm (14")  | 76 mm (3") | 1.5, 2 above 110, 2.5 above 200°C | Yes                |
| GT-30555T                             | Yellow Back | 20/500°F  | 2         | 350 mm (14")  | 76 mm (3") | 1.5, 2 above 230, 2.5 above 392°F | Yes                |
| GT-38110                              | White Back  | -10/110°C | 1         | 200 mm (7.9") | 50 mm (2") | 1.5                               | No                 |
| GT-38150                              | White Back  | -10/150°C | 1         | 200 mm (7.9") | 50 mm (2") | 1.5, 2 above 100°C                | No                 |
| GT-38230                              | White Back  | 20/230°F  | 2         | 200 mm (7.9") | 50 mm (2") | 1.5, 2 above 212°F                | No                 |
| GT-35110                              | White Back  | -20/110°C | 1         | 300 mm (12")  | 76 mm (3") | 1.5                               | No                 |
| GT-35150                              | White Back  | -20/150°C | 1         | 300 mm (12")  | 76 mm (3") | 1.5, 2 above 100°C                | No                 |
| GT-35200                              | White Back  | -10/200°C | 1         | 300 mm (12")  | 76 mm (3") | 2, 2.5 above 100°C                | No                 |
| GT-35230                              | White Back  | 0/230°F   | 2         | 300 mm (12")  | 76 mm (3") | 1.5, 2 above 212°F                | No                 |
| GT-35300                              | White Back  | 0/300°F   | 2         | 300 mm (12")  | 76 mm (3") | 1.5, 2 above 212°F                | No                 |



**PFA Safety Coated Liquid-In-Glass Thermometers (continued)**

| <b>To Order</b>                     |             |              |                  |               |                  |                                       |                               |
|-------------------------------------|-------------|--------------|------------------|---------------|------------------|---------------------------------------|-------------------------------|
| <b>Model No.</b>                    | <b>Type</b> | <b>Range</b> | <b>Divisions</b> | <b>Length</b> | <b>Immersion</b> | <b>Accuracy<br/>(Scale Divisions)</b> | <b>Traceable<br/>to DAkkS</b> |
| <b>Total Immersion Thermometers</b> |             |              |                  |               |                  |                                       |                               |
| <b>GT-30592T</b>                    | Yellow Back | -10/110°C    | 1                | 200 mm (7.9") | Total            | 1                                     | Yes                           |
| <b>GT-30594T</b>                    | Yellow Back | -10/150°C    | 1                | 200 mm (7.9") | Total            | 1, 1.5 above 110°C                    | Yes                           |
| <b>GT-30596T</b>                    | Yellow Back | 20/230°F     | 2                | 200 mm (7.9") | Total            | 1                                     | Yes                           |
| <b>GT-30598T</b>                    | Yellow Back | 20/300°F     | 2                | 200 mm (7.9") | Total            | 1, 1.5 above 230°F                    | Yes                           |
| <b>GT-30500T</b>                    | Yellow Back | -20/110°C    | 1                | 300 mm (12")  | Total            | 1                                     | Yes                           |
| <b>GT-30510T</b>                    | Yellow Back | -20/150°C    | 1                | 300 mm (12")  | Total            | 1, 1.5 above 110°C                    | Yes                           |
| <b>GT-30530T</b>                    | Yellow Back | 0/230°F      | 2                | 300 mm (12")  | Total            | 1                                     | Yes                           |
| <b>GT-30540T</b>                    | Yellow Back | 0/300°F      | 2                | 300 mm (12")  | Total            | 1, 1.5 above 230°F                    | Yes                           |
| <b>GT-30520T</b>                    | Yellow Back | -10/225°C    | 1                | 350 mm (14")  | Total            | 1.5, 2 above 110,<br>2.5 above 200°C  | Yes                           |
| <b>GT-30550T</b>                    | Yellow Back | 20/440°F     | 2                | 350 mm (14")  | Total            | 1.5, 2 above 230,<br>2.5 above 392°F  | Yes                           |
| <b>GT-37110</b>                     | White Back  | -10/110°C    | 1                | 200 mm (7.9") | Total            | 1.5                                   | No                            |
| <b>GT-37150</b>                     | White Back  | -10/150°C    | 1                | 200 mm (7.9") | Total            | 1.5, 2 above 100°C                    | No                            |
| <b>GT-36110</b>                     | White Back  | -20/110°C    | 1                | 300 mm (12")  | Total            | 1.5                                   | No                            |
| <b>GT-36150</b>                     | White Back  | -20/150°C    | 1                | 300 mm (12")  | Total            | 1.5, 2 above 100°C                    | No                            |
| <b>GT-36230</b>                     | White Back  | 0/230°F      | 2                | 300 mm (12")  | Total            | 1.5, 2 above 212°F                    | No                            |