



NEMA TYPE 4X ENVIROLINE® SERIES 304 STAINLESS STEEL ENCLOSURES

SCE-EL Series



SCE-12EL1206SSLP
shown smaller than actual size.

- 0.075" Stainless Steel Type 304
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- Oil-Resistant Gasket
- Collar Studs Provided for Mounting Optional Sub-Panels
- Stainless Steel Concealed Hinge
- Removable and Interchangeable Doors
- Black Quarter Turn Latches
- Latches Are Opened or Closed With a Screwdriver (Optional Tamper-Resistant Inserts Are Available)
- Mounting Holes In Back of Enclosure
- Mounting Hardware, Sealing Washer and Hole Plug Included
- Removable Print Pocket
- Ground Studs On Door and Body
- Optional Mounting Feet Available
- Door Hardware Available
- Panel Can Be Special Ordered in Stainless Steel Up to 48P36 Size

Application


Designed to house electrical and electronic controls, instruments and components in areas which may be regularly hosed down or are in very wet conditions. Provides protection from dust, dirt, oil and water. For outdoor application a drip shield is recommended.

Finish

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 4X, 12 & 13; UL Listed Type 4, 4X & 12; CSA Type 4, 4X & 12; IEC 60529 IP 66

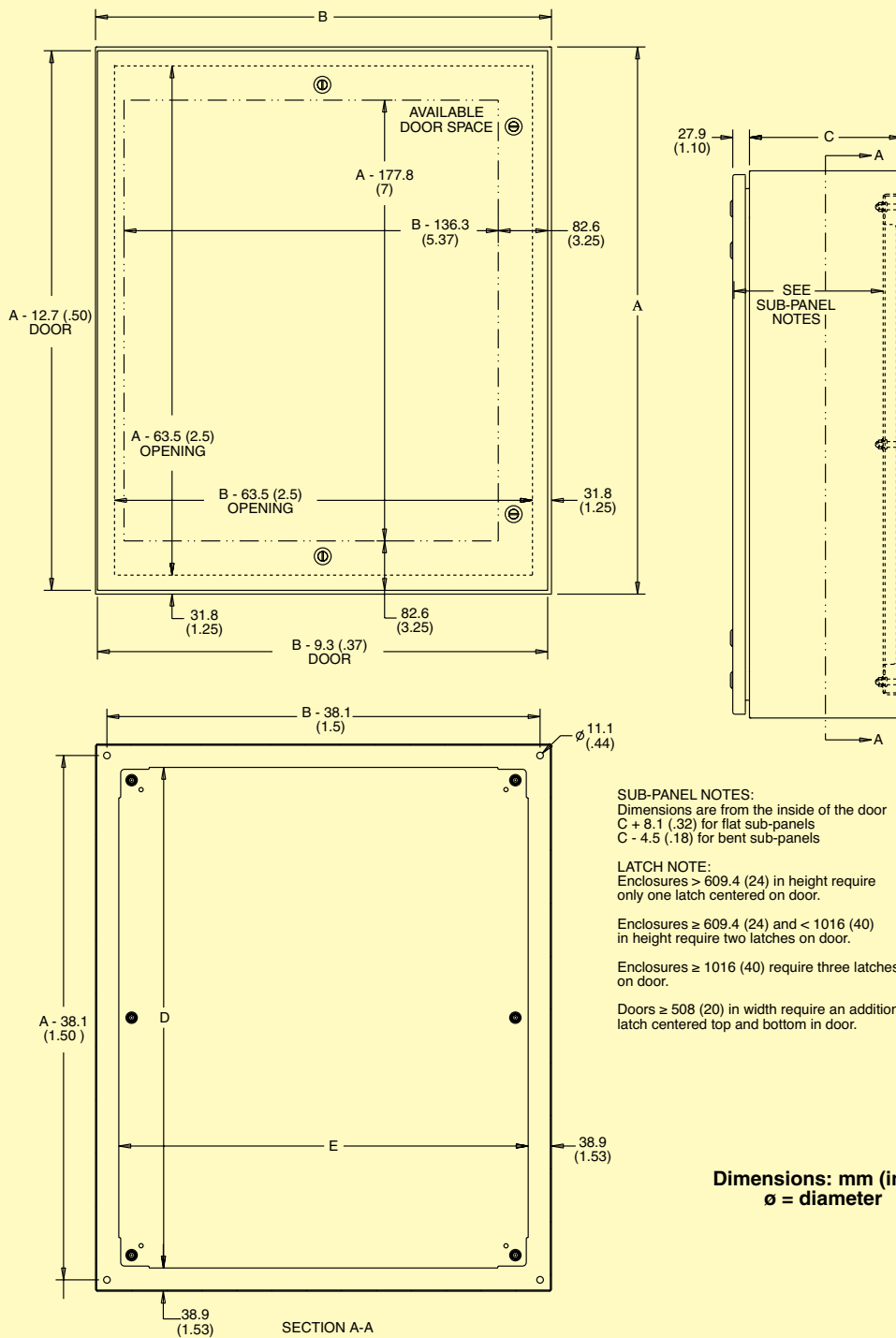

To Order Visit omega.com/sce_el for Pricing and Details

TYPE 4X 304 STAINLESS STEEL ENVIROLINE® SERIES ENCLOSURES

MODEL NO.	ENCLOSURES (inch)			SUB-PANEL (inch)		
	HEIGHT (A)	WIDTH (B)	DEPTH (C)	HEIGHT MODEL NO.	WIDTH (D)	(E)
SCE-12EL1206SSLP	12.00	12.00	6.00	SCE-12DLP12	9.00	9.00
SCE-12EL2406SSLP	12.00	24.00	6.00	SCE-12P24	9.00	21.00
SCE-16EL1206SSLP	16.00	12.00	6.00	SCE-16P12	13.00	9.00
SCE-16EL1208SSLP	16.00	12.00	8.00	SCE-16P12	13.00	9.00
SCE-16EL1606SSLP	16.00	16.00	6.00	SCE-16P16	13.00	13.00
SCE-16EL1608SSLP	16.00	16.00	8.00	SCE-16P16	13.00	13.00

To Order Visit omega.com/sce_el for Pricing and Details

TYPE 4X 304 STAINLESS STEEL ENVIROLINE® SERIES ENCLOSURES (CONTINUED)

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-16EL2008SSLP	16.00	20.00	8.00	SCE-20P16	17.00	13.00
SCE-20EL1606SSLP	20.00	16.00	6.00	SCE-20P16	17.00	13.00
SCE-20EL1608SSLP	20.00	16.00	8.00	SCE-20P16	17.00	13.00
SCE-20EL1610SSLP	20.00	16.00	10.00	SCE-20P16	17.00	13.00
SCE-20EL2006SSLP	20.00	20.00	6.00	SCE-20P20	17.00	17.00
SCE-20EL2008SSLP	20.00	20.00	8.00	SCE-20P20	17.00	17.00
SCE-20EL2010SSLP	20.00	20.00	10.00	SCE-20P20	17.00	17.00
SCE-20EL2408SSLP	20.00	24.00	8.00	SCE-24P20	21.00	17.00
SCE-24EL1608SSLP	24.00	16.00	8.00	SCE-24P16	21.00	13.00
SCE-24EL2006SSLP	24.00	20.00	6.00	SCE-24P20	21.00	17.00
SCE-24EL2008SSLP	24.00	20.00	8.00	SCE-24P20	21.00	17.00
SCE-24EL2010SSLP	24.00	20.00	10.00	SCE-24P20	21.00	17.00
SCE-24EL2012SSLP	24.00	20.00	12.00	SCE-24P20	21.00	17.00
SCE-24EL2408SSLP	24.00	24.00	8.00	SCE-24P24	21.00	21.00
SCE-24EL2410SSLP	24.00	24.00	10.00	SCE-24P24	21.00	21.00
SCE-24EL2412SSLP	24.00	24.00	12.00	SCE-24P24	21.00	21.00
SCE-24EL2416SSLP	24.00	24.00	16.00	SCE-24P24	21.00	21.00
SCE-24EL3008SSLP	24.00	30.00	8.00	SCE-30P24	27.00	21.00
SCE-24EL3010SSLP	24.00	30.00	10.00	SCE-30P24	27.00	21.00
SCE-30EL1606SSLP	30.00	16.00	6.00	SCE-30P16	27.00	13.00
SCE-30EL2008SSLP	30.00	20.00	8.00	SCE-30P20	27.00	17.00
SCE-30EL2010SSLP	30.00	20.00	10.00	SCE-30P20	27.00	17.00
SCE-30EL2408SSLP	30.00	24.00	8.00	SCE-30P24	27.00	21.00
SCE-30EL2410SSLP	30.00	24.00	10.00	SCE-30P24	27.00	21.00
SCE-30EL2412SSLP	30.00	24.00	12.00	SCE-30P24	27.00	21.00
SCE-30EL2416SSLP	30.00	24.00	16.00	SCE-30P24	27.00	21.00
SCE-30EL3008SSLP	30.00	30.00	8.00	SCE-30P30	27.00	27.00
SCE-30EL3010SSLP	30.00	30.00	10.00	SCE-30P30	27.00	27.00
SCE-30EL3012SSLP	30.00	30.00	12.00	SCE-30P30	27.00	27.00
SCE-30EL3608SSLP	30.00	36.00	8.00	SCE-36P30	33.00	27.00
SCE-36EL2408SSLP	36.00	24.00	8.00	SCE-36P24	33.00	21.00
SCE-36EL2410SSLP	36.00	24.00	10.00	SCE-36P24	33.00	21.00
SCE-36EL3008SSLP	36.00	30.00	8.00	SCE-36P30	33.00	27.00
SCE-36EL3010SSLP	36.00	30.00	10.00	SCE-36P30	33.00	27.00
SCE-36EL3012SSLP	36.00	30.00	12.00	SCE-36P30	33.00	27.00
SCE-36EL3608SSLP	36.00	36.00	8.00	SCE-36P36	33.00	33.00
SCE-36EL3612SSLP	36.00	36.00	12.00	SCE-36P36	33.00	33.00
SCE-42EL2410SSLP	42.00	24.00	10.00	SCE-42P24	39.00	21.00
SCE-42EL3010SSLP	42.00	30.00	10.00	SCE-42P30	39.00	27.00
SCE-42EL3612SSLP	42.00	36.00	12.00	SCE-42P36	39.00	33.00
SCE-42EL3616SSLP	42.00	36.00	16.00	SCE-42P36	39.00	33.00
SCE-48EL3612SSLP	48.00	36.00	12.00	SCE-48P36	45.00	33.00
SCE-48EL3616SSLP	48.00	36.00	16.00	SCE-48P36	45.00	33.00
SCE-60EL3612SSLP	60.00	36.00	12.00	SCE-60P36	57.00	33.00
SCE-60EL3616SSLP	60.00	36.00	16.00	SCE-60P36	57.00	33.00
SCE-72EL3016SSLP	72.00	30.00	16.00	SCE-72P30	69.00	27.00
SCE-72EL3612SSLP	72.00	36.00	12.00	SCE-72P36	69.00	33.00
SCE-72EL3616SSLP	72.00	36.00	16.00	SCE-72P36	69.00	33.00

Ordering Examples: SCE-12EL1206SSLP, Type 4X 304 stainless steel Enviroline® series enclosure.

SCE-24EL2008SSLP, Type 4 series Enviroline stainless steel enclosure, 24 H x 20 W x 8" D, SCE-24P20, sub-panel.