


NEMA TYPE 4X ENVIROLINE® 304 AND 316 SS TWO-DOOR ENCLOSURES

SCE-ELSSLP Series



- 0.104" Stainless Steel Type 304 and 316
- Seams Continuously Welded and Ground Smooth
- Oil-Resistant Gasket
- Flange Trough Collar Around All Sides of Door Opening
- Stainless Steel Concealed Hinge
- Removable and Interchangeable Doors
- Removable Print Pocket
- Lifting Eyes for Easy Handling
- Ground Stud On Door and Body
- Collar Studs Provided for Mounting Optional Panels
- 12" Removable Floor Stands
- Removable Center Post
- No Door Stiffener Required
- Padlocking/Keylocking Handle with 3-Point Operating Mechanism and Tamper-Resistant Hardware Included

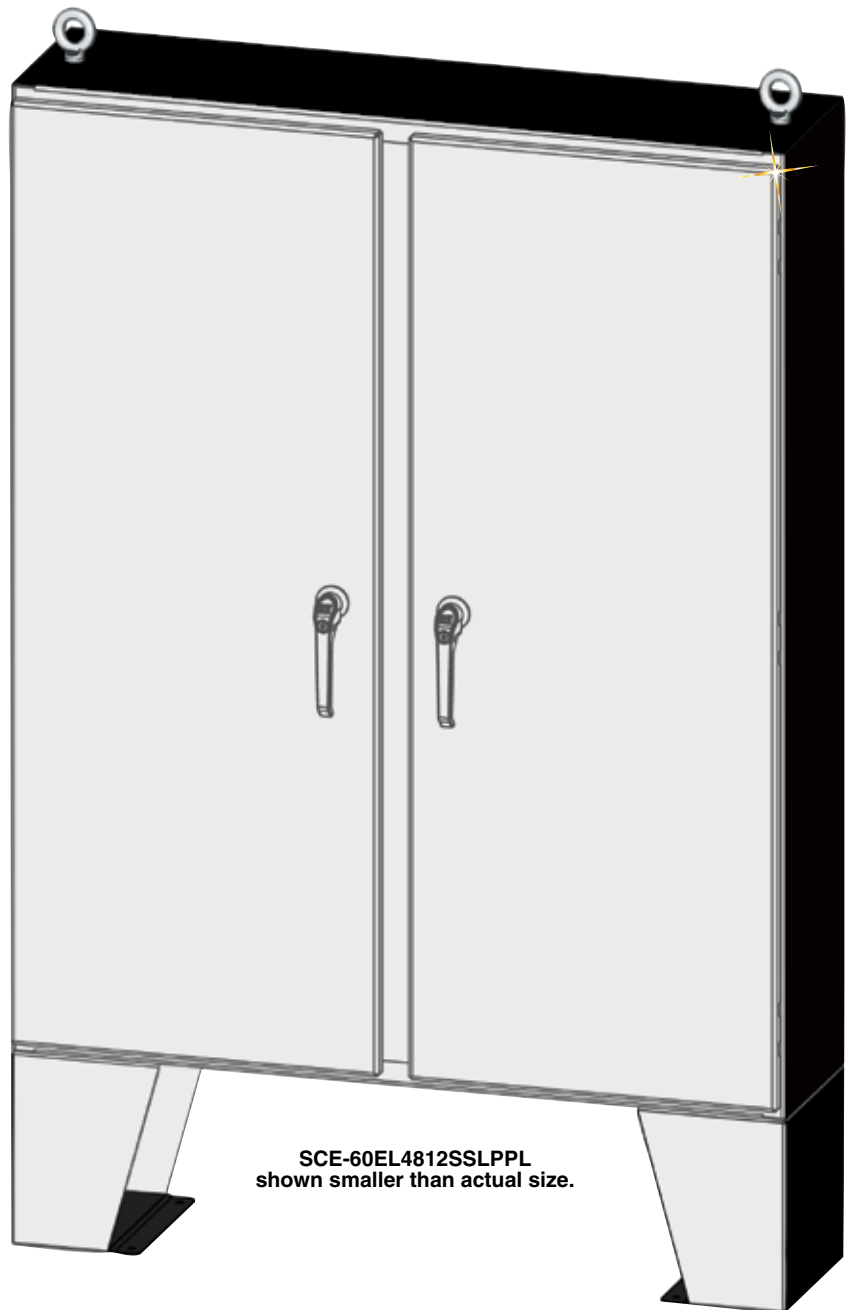

SCE-60EL4812SSLPPL
shown smaller than actual size.

Application

Designed to house electrical and electronic controls, instruments and components. Provides protection from dust, oil and strong jets of water.


Finish

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standard IS5

NEMA Type 4, 4X, 12 & 1; UL Listed Type 4, 4X & 12;
CSA Type 4, 4X & 12; IEC 60529 IP66

Dimensions: inch (mm)

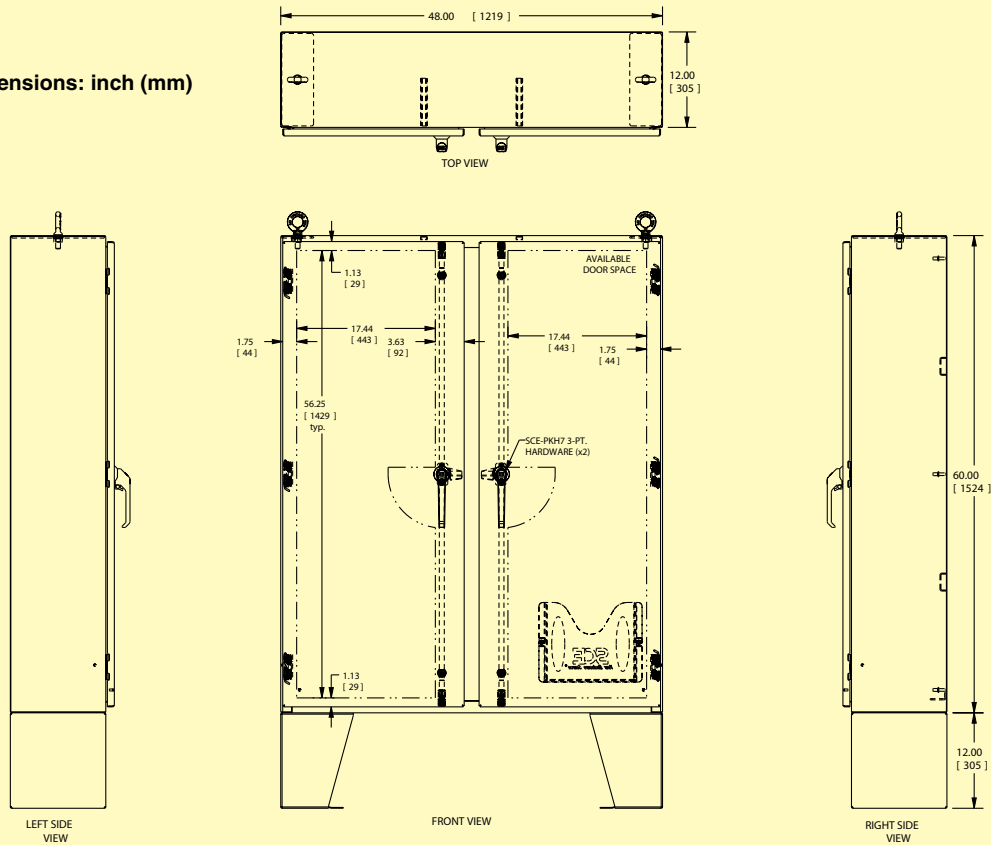

To Order

TYPE 4X 304 STAINLESS STEEL ENVIROLINE SERIES TWO-DOOR ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-60EL4812SSLPPL	60.00	48.00	12.00	SCE-60P48	56.00	44.00
SCE-60EL4818SSLPPL	60.00	48.00	18.00	SCE-60P48	56.00	56.00
SCE-60EL6012SSLPPL	60.00	60.00	12.00	SCE-60P60	56.00	56.00
SCE-60EL6018SSLPPL	60.00	60.00	18.00	SCE-60P60	56.00	56.00
SCE-72EL6012SSLPPL	72.00	60.00	12.00	SCE-72P60	68.00	68.00
SCE-72EL6018SSLPPL	72.00	60.00	18.00	SCE-72P60	68.00	56.00
SCE-72EL7212SSLPPL	72.00	72.00	12.00	SCE-72P72	68.00	68.00
SCE-72EL7218SSLPPL	72.00	72.00	18.00	SCE-72P72	68.00	68.00
SCE-72EL7224SSLPPL	72.00	72.00	24.00	SCE-72P72	68.00	68.00

TYPE 4X 316 STAINLESS STEEL ENVIROLINE SERIES TWO-DOOR ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-60EL4812SS6LPPL	60.00	48.00	12.00	SCE-60P48	56.00	44.00
SCE-60EL4818SS6LPPL	60.00	48.00	18.00	SCE-60P48	56.00	56.00
SCE-60EL6012SS6LPPL	60.00	60.00	12.00	SCE-60P60	56.00	56.00
SCE-60EL6018SS6LPPL	60.00	60.00	18.00	SCE-60P60	56.00	56.00
SCE-72EL6012SS6LPPL	72.00	60.00	12.00	SCE-72P60	68.00	68.00
SCE-72EL6018SS6LPPL	72.00	60.00	18.00	SCE-72P60	68.00	56.00
SCE-72EL7212SS6LPPL	72.00	72.00	12.00	SCE-72P72	68.00	68.00
SCE-72EL7218SS6LPPL	72.00	72.00	18.00	SCE-72P72	68.00	68.00
SCE-72EL7224SS6LPPL	72.00	72.00	24.00	SCE-72P72	68.00	68.00

Ordering Examples: SCE-60EL4812SSLPPL, Type 4X 304 stainless steel Enviroline® series two-door enclosure.

SCE-60EL4818SSLPPL Type 4X 304 stainless steel Enviroline® series two-door enclosure, SCE-60P48 sub-panel for 60 x 48" enclosure.