

NEMA TYPE 4X 304 SS SINGLE-DOOR ENCLOSURES

SCE-SSLP Series



- 0.075" 304 Stainless Steel
- No Holes or Knockouts, Continuously Welded Seams Ground Smooth
- Flange Trough Collar Around All Sides Of Door Opening
- Oil-Resistant Door Gasket
- Collar Studs Provided for Mounting Optional Sub-Panels
- Hasp and Staple For Padlocking
- Stainless Steel Continuous Hinge
- Print Pocket
- Ground Stud On Door
- Stainless Steel Clamps On Three Sides of Door Will Keep Out All Liquids and Other Contaminants
- Panel Can Be Special Ordered in Stainless Steel Up to 48P36 Size

Application

Designed to house electrical and electronic controls, instruments and components in areas which may be regularly hosed down or are in very wet conditions. Provides protection from dust, dirt, oil and water. For outdoor application a drip shield is recommended.

Finish




#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 4X, 12 & 13
UL Listed Type 4, 4X & 12
CSA Type 4, 4X & 12
IEC 60529 IP 66



SCE-16H1206SSLP
shown smaller than
actual size.

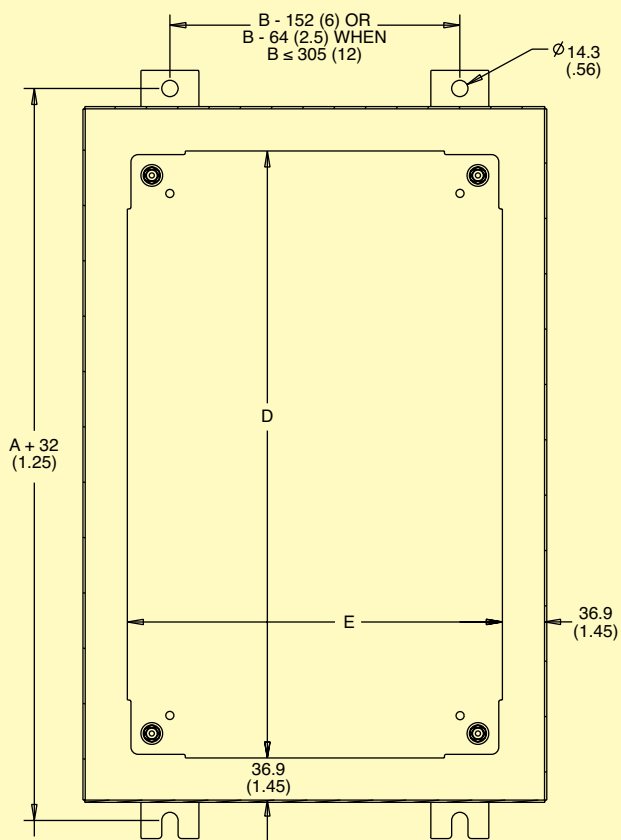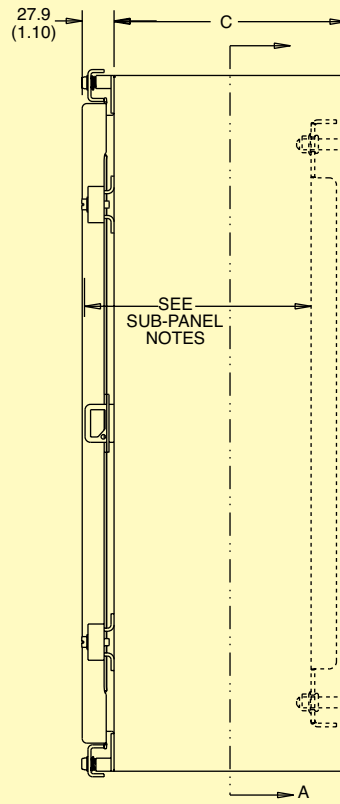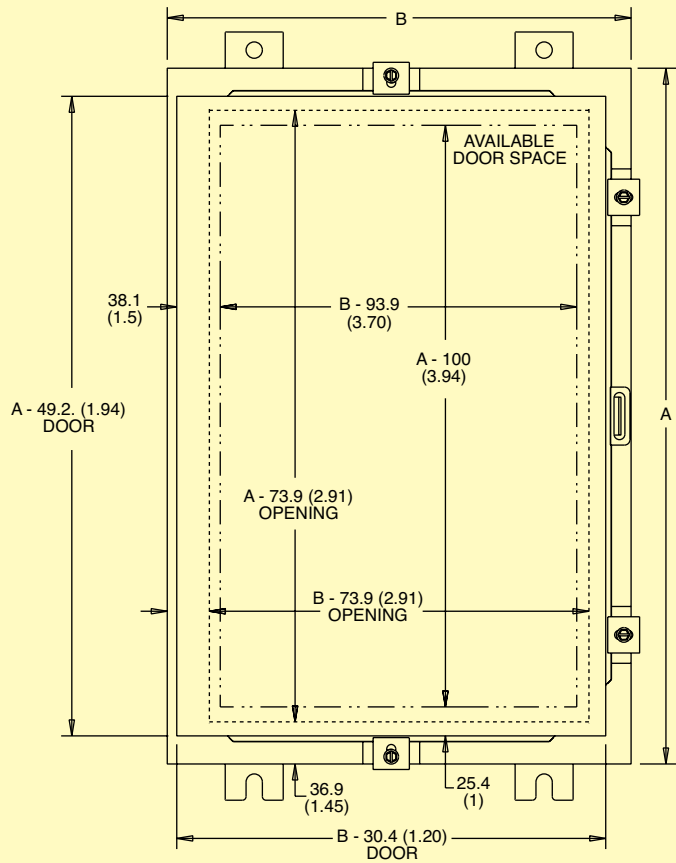

SECTION A-A

SUB-PANEL NOTES:
 Dimensions are from the inside of the door
 C + 8.1 (.32) for flat sub-panels
 C - 4.5 (.18) for bent sub-panels

CLAMPING NOTES:
 Enclosures > 610 (24) in height require
 a third clamp centered vertically on door

Dimensions: mm (inch)



SCE-16H1206SSLP
shown smaller
than actual size.

To Order

TYPE 4X 304 STAINLESS STEEL SINGLE-DOOR ENCLOSURES

ENCLOSURES (inch)				STEEL SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-16H1206SSLP	16.00	12.00	6.00	SCE-16P12	13.00	9.00
SCE-16H1208SSLP	16.00	12.00	8.00	SCE-16P12	13.00	9.00
SCE-16H1606SSLP	16.00	16.00	6.00	SCE-16P16	13.00	13.00
SCE-16H2006SSLP	16.00	20.00	6.00	SCE-20P16	17.00	13.00
SCE-20H1606SSLP	20.00	16.00	6.00	SCE-20P16	17.00	13.00
SCE-20H1608SSLP	20.00	16.00	8.00	SCE-20P16	17.00	13.00
SCE-20H1610SSLP	20.00	16.00	10.00	SCE-20P16	17.00	13.00
SCE-20H2006SSLP	20.00	20.00	6.00	SCE-20P20	17.00	17.00
SCE-20H2408SSLP	20.00	24.00	8.00	SCE-24P20	21.00	17.00
SCE-24H1608SSLP	24.00	16.00	8.00	SCE-24P16	21.00	13.00
SCE-24H2006SSLP	24.00	20.00	6.00	SCE-24P20	21.00	17.00
SCE-24H2008SSLP	24.00	20.00	8.00	SCE-24P20	21.00	17.00
SCE-24H2010SSLP	24.00	20.00	10.00	SCE-24P20	21.00	17.00
SCE-24H2408SSLP	24.00	24.00	8.00	SCE-24P24	21.00	21.00
SCE-24H2412SSLP	24.00	24.00	12.00	SCE-24P24	21.00	21.00
SCE-24H3008SSLP	24.00	30.00	8.00	SCE-30P24	27.00	21.00
SCE-30H2008SSLP	30.00	20.00	8.00	SCE-30P20	27.00	17.00
SCE-30H2408SSLP	30.00	24.00	8.00	SCE-30P24	27.00	21.00
SCE-30H2412SSLP	30.00	24.00	12.00	SCE-30P24	27.00	21.00
SCE-30H2416SSLP	30.00	24.00	16.00	SCE-30P24	27.00	21.00
SCE-30H3008SSLP	30.00	30.00	8.00	SCE-30P30	27.00	27.00
SCE-36H2408SSLP	36.00	24.00	8.00	SCE-36P24	33.00	21.00
SCE-36H2410SSLP	36.00	24.00	10.00	SCE-36P24	33.00	21.00
SCE-36H3008SSLP	36.00	30.00	8.00	SCE-36P30	33.00	27.00
SCE-36H3010SSLP	36.00	30.00	10.00	SCE-36P30	33.00	27.00
SCE-36H3012SSLP	36.00	30.00	12.00	SCE-36P30	33.00	27.00
SCE-36H3016SSLP	36.00	30.00	16.00	SCE-36P30	33.00	27.00
SCE-36H3612SSLP	36.00	36.00	12.00	SCE-36P36	33.00	33.00
SCE-42H3010SSLP	42.00	30.00	10.00	SCE-42P30	39.00	27.00
SCE-42H3608SSLP	42.00	36.00	8.00	SCE-42P36	39.00	33.00
SCE-48H3608SSLP	48.00	36.00	8.00	SCE-48P36	45.00	33.00
SCE-48H3612SSLP	48.00	36.00	12.00	SCE-48P36	45.00	33.00
SCE-48H3616SSLP	48.00	36.00	16.00	SCE-48P36	45.00	33.00
SCE-60H3612SSLP	60.00	36.00	12.00	SCE-60P36	57.00	33.00

Ordering Examples: SCE-16H1206SSLP, Type 4X, 304 stainless steel, single door enclosure.

SCE-20H2408SSLP, Type 4X, 304 SS, single-door enclosure, 20 H x 24 W x 8" D, SCE-24P20, sub-panel.