

NEMA TYPE 4 ENVIROLINE® SERIES SINGLE-DOOR ENCLOSURES

FOR FLANGE MOUNTED DISCONNECTS



SCE-20XEL2108LP shown
smaller than actual size.

- 0.075" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides Of Door Opening
- Oil-Resistant Gasket
- Collar Studs Provided for Mounting Optional Panels
- Disconnect Cutout Provided On Flange
- Concealed Hinge
- Doors Are Interchangeable and Easily Removed By Pulling Hinge Pins
- 3-Point Latching Mechanism
- Latches Are Opened Or Closed With A Screwdriver (Optional Tamper-Resistant Inserts Are Available)
- Mounting Holes on Back of Enclosure
- Mounting Hardware, Sealing Washer and Hole Plug Included
- Ground Stud On Door and Body
- Black Zinc Die Cast Coinproof/ Padlocking Handle
- Disconnect Switch (or Circuit Breaker) and Operating Mechanism Are Not Furnished with This Enclosure

Application


Disconnect enclosure Type 1 is designed to house most standard type disconnects. Contact Omega to verify compatibility of a specific disconnect or circuit breaker, and for wire bend space. For outdoor application a drip shield is recommended.

Finish

ANSI-61 gray powder coating inside and out over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 12 & 13
UL Listed Type 4, & 12
CSA Type 4 & 12
IEC 60529 IP 66

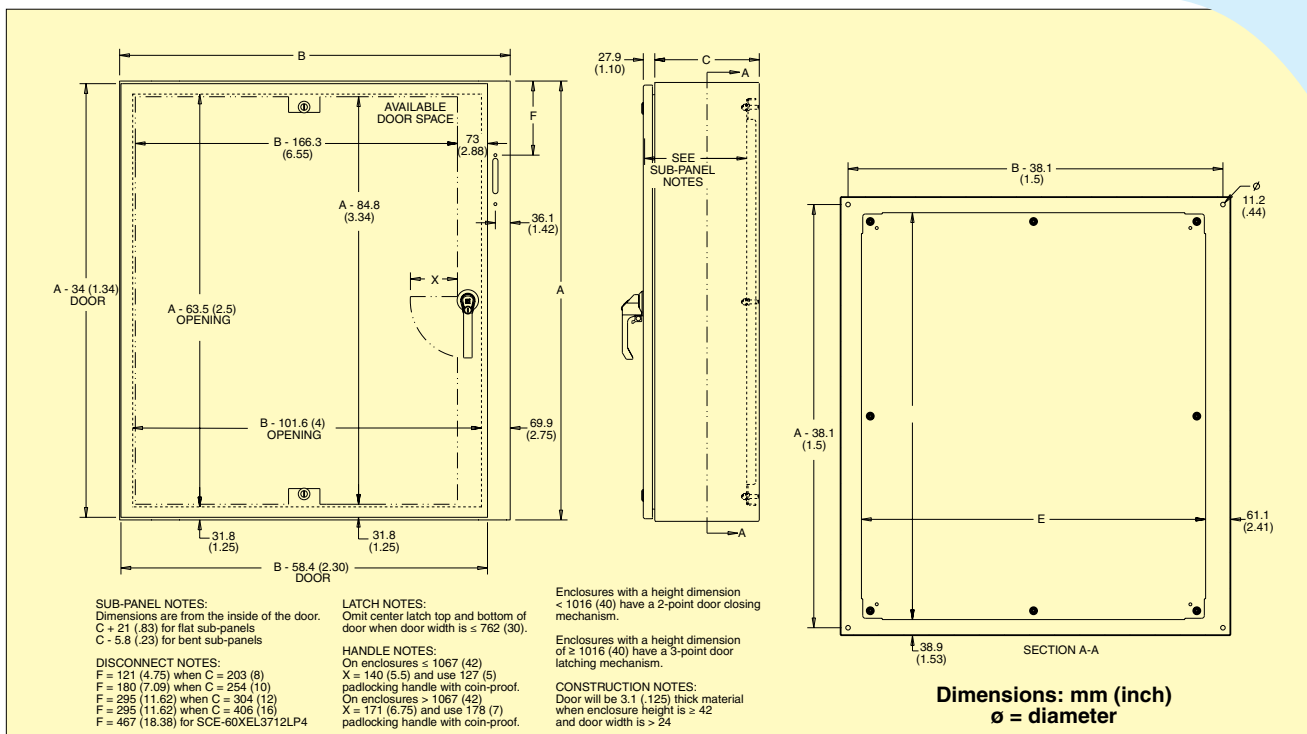

To Order

TYPE 4 ENVIROLINE® SERIES SINGLE-DOOR FOR FLANGE MOUNTED DISCONNECTS

MODEL NO.	ENCLOSURES (inch)			SUB-PANEL (inch)		
	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-20XEL2108LP	20.00	21.38	8.00	SCE-20P20	17.00	17.00
SCE-20XEL2110LP	20.00	21.38	10.00	SCE-20P20	17.00	17.00
SCE-24XEL2108LP	24.00	21.38	8.00	SCE-24P20	21.00	17.00
SCE-24XEL2508LP	24.00	25.38	8.00	SCE-24P24	21.00	21.00
SCE-24XEL2510LP	24.00	25.38	10.00	SCE-24P24	21.00	21.00
SCE-30XEL2508LP	30.00	25.38	8.00	SCE-30P24	27.00	21.00
SCE-30XEL2510LP	30.00	25.38	10.00	SCE-30P24	27.00	21.00
SCE-36XEL2508LP	36.00	25.38	8.00	SCE-36P24	33.00	21.00
SCE-36XEL2510LP	36.00	25.38	10.00	SCE-36P24	33.00	21.00
SCE-36XEL3108LP	36.00	31.38	8.00	SCE-36P30	33.00	27.00
SCE-36XEL3110LP	36.00	31.38	10.00	SCE-36P30	33.00	27.00
SCE-36XEL3112LP	36.00	31.38	12.00	SCE-36P30	33.00	27.00
SCE-36XEL3116LP	36.00	31.38	16.00	SCE-36P30	33.00	27.00
SCE-42XEL3110LP	42.00	31.38	10.00	SCE-42P30	39.00	27.00
SCE-42XEL3112LP	42.00	31.38	12.00	SCE-42P30	39.00	27.00
SCE-42XEL3116LP	42.00	31.38	16.00	SCE-42P30	39.00	27.00
SCE-42XEL3710LP	42.00	37.38	10.00	SCE-42P36	39.00	33.00
SCE-42XEL3712LP	42.00	37.38	12.00	SCE-42P36	39.00	33.00
SCE-42XEL3716LP	42.00	37.38	16.00	SCE-42P36	39.00	33.00
SCE-48XEL3710LP	48.00	37.38	10.00	SCE-48P36	45.00	33.00
SCE-48XEL3712LP	48.00	37.38	12.00	SCE-48P36	45.00	33.00
SCE-48XEL3716LP	48.00	37.38	16.00	SCE-48P36	45.00	33.00
SCE-60XEL3710LP	60.00	37.38	10.00	SCE-60P36	57.00	33.00
SCE-60XEL3712LP	60.00	37.38	12.00	SCE-60P36	57.00	33.00
SCE-60XEL3712LP4*	60.00	37.38	12.00	SCE-60P36	57.00	33.00
SCE-60XEL3716LP	60.00	37.38	16.00	SCE-60P36	57.00	33.00

* Indicates provision for 400 A disconnect.

Ordering Examples: SCE-20XEL2108LP, Type 4 Enviroline® series single-door enclosure for flange-mounted disconnects.

SCE-24XEL2510LP, Type 4 Enviroline® series single-door enclosure, 24 H x 25.38 W x 10" D, SCE-24P24, sub-panel for 24 x 25" enclosure.