


Tank Immersion Heaters

Sanitizing Sink Immersion Heaters

TAT4 Series

- ✓ Used for Sterilization of Water Tanks in Restaurants, Taverns and Laboratories
- ✓ Double Pole 16 to 121°C (60 to 250°F) Thermostat with Over-Temperature Cutout; Optional Pilot Lamp to Indicate Heater On/Off Status Available
- ✓ Standard 1.8 m (6') with Grounding Plug [NEMA 5 to 15P for 120V and 6 to 30P for 240V]
- ✓ Adjustable Stainless Steel Mounting Bracket
- ✓ Contact OMEGA for Custom Designs

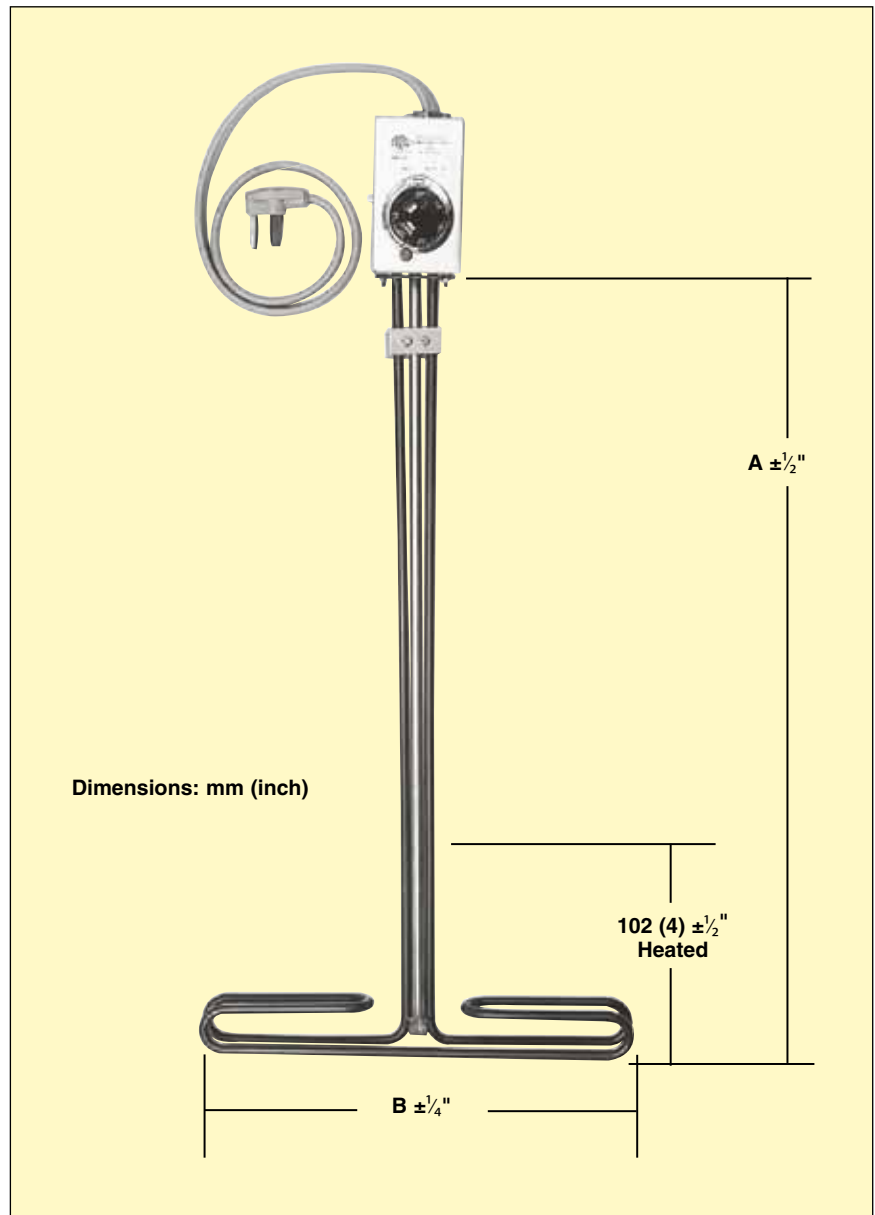

Note: Not for Export to Canada

To Order								
Model No.	Sheath	Watt Density watt/in ²	Watts	Volts	A		B	
					mm	inch	mm	inch
TAT40001	316	65	6000	240			432	17
TAT40002	Stainless Steel	56	4000	240			330	13
TAT40003	(Electropolished)	16	1500	120	660	26	432	17
TAT40004		14	1000	120			330	13
TAT40005	316	65	6000	240			432	17
TAT40006	Stainless Steel	56	4000	240			330	13
TAT40007	(Bright Annealed)	16	1500	120	660	26	432	17
TAT40008		14	1000	120			330	13

Comes complete with 1.8 m (6') cord set with grounding plug.

Ordering Example: TAT40001, 6000 watts immersion heater, 240 Vac.